


Metal Connection Kit, Cold-Applied

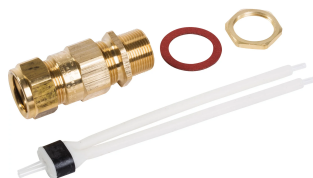

nVent RAYCHEM C25-100-METAL and C3/4-100-METAL are cold-applied metal connection kits for terminating all nVent RAYCHEM self-regulating and power-limiting industrial parallel heating cables to a metal or plastic junction box with internal earthing plate. C25-100-METAL for M25 entries, C3/4-100-METAL: for 3/4" NPT entries.

KENMERKEN

Simple and fast to install

Cold-applied: core sealing boot with non-curing sealant; no heat gun, no hot work permit needed

One component for all nVent RAYCHEM industrial parallel heating cables

Simplified design in hazardous area, integral part of system approval

Reliable during long life: 10 year extended product warranty available, maintenance free

SPECIFICATIES

Max Exposure Temperature: 180 °C

Aansluiting type: Cold Applied

Model: Connection to Junction Box

Table 1/1

Catalogusnummer	Naam van het item	Formaat draad
1244-001350	C3/4-100-METAL-NP	3/4"
440588-000	C3/4-100-METAL	3/4"
875016-000	C25-100-METAL	M25 x 1.5
1244-002296	C25-100-METAL-NP	M25 x 1.5

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.

Noord-Amerika

Tel +1.800.545.6258

Fax +1.800.527.5703

thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

cn.thermal.info@nvent.com

Latijns-Amerika

Tel +1.713.868.4800

Fax +1.713.868.2333

thermal.info@nvent.com

Our powerful portfolio of brands:

RAYCHEM PYROTENAX TRACER NUHEAT