
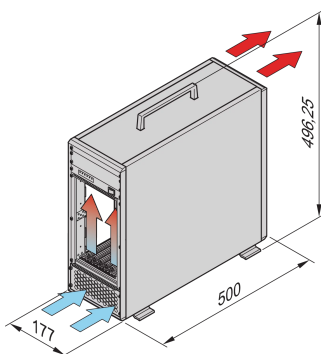


VME64x System, Tower, 4 U, Open Frame PSU

CATALOGUSNUMMER

10836-050

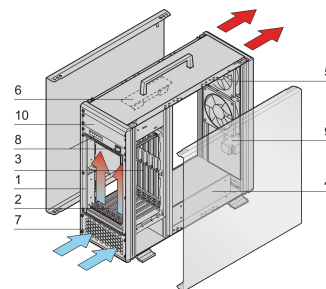

VME64 tower system for 7 VME64x boards 6 U, 160 mm. The power for the system is supplied by a open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICERINGEN



KENMERKEN

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 560 W (400 W at < 180 VAC)

Backplane VME64x 7 slot, 6 U, J1/J2 monolithic without P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 2 fans, cooling from front to rear side; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep

Display module for DC operating voltages, fan and temperature alarm

Option to mount a 5.25" DVD drive unit

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 7

Type: Toren

Type achterzijde: 6 U VME64-verlenging

Gegevensoverdracht: VME64; VME2eSST

Vermogen per sleuf: 30W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Voor naar achter

Rekhoogte: 10U

Type voeding: Open frame

Voeding inbegrepen: Ja

I/O achter: Nee

Voldoet aan: ANSI/VITA 1.1-1997

Diepte: 500mm

Hoogte: 496.25mm

Breedte: 177mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE