


VME64x-systeem, 2 u, 4 sleuven, insteekbare voeding

CATALOGUSNUMMER

20836-245

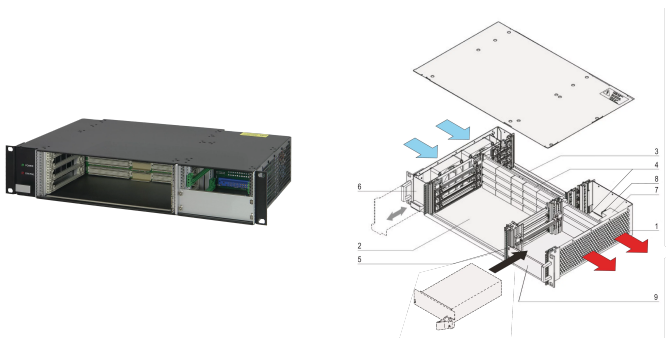

VME64x system for 4 horizontally mounted VME64x boards 6 U, 160 mm. Rear I/ O option. The power for the system is supplied by up to two pluggable power supplies. A hot swap fan tray with 4 fans guarantee an excellent cooling.

CERTIFICERINGEN



KENMERKEN

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

Power backplane to PICMG 2.11 (P 47), prepared for installation of two 19" compatible PSUs, 300 W (3 U, 8 HP)

Heat dissipation by a fan tray with 2 fans, cooling from right to left side; fan monitoring and voltage display

System for horizontal board mounting with board formats; Front: 6 U, 160 mm deep; Rear, rear I/O: 6 U, 80 mm deep

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 4

Type: 19 inch rekmontage

Type achterzijde: 6 U VME64-verlenging

Gegevensoverdracht: VME64; VME2eSST

Vermogen per sleuf: 30W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Links naar rechts

Rekhoogte: 2U

Type voeding: (2) Insteekbare voeding

Voeding inbegrepen: Nee

I/O achter: Ja

Voldoet aan: ANSI/VITA 1.1-1997

Diepte: 277.5mm

Hoogte: 88.1mm

Breedte: 449mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE