


VMEbus System, 4 U, 8 Slot, Open Frame PSU

CATALOGUSNUMMER

20836-415

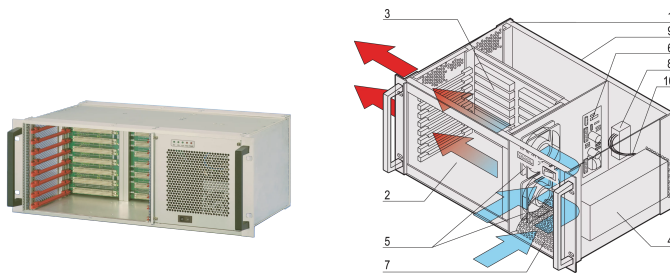

VME system for 8 horizontally mounted VME boards 6 U, 160 mm. The power for the system is supplied by an open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICERINGEN



KENMERKEN

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; Backplane conforms to VITA 1.1-1994

PSU, open frame, 444 W (400 W at < 180 VAC)

Backplane VME 8 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

Heat dissipation by 2 fans, cooling from front to left side; temperature-controlled with fan control module (FCM)

Display module for DC operating voltages, fan and temperature alarm

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 8

Type: 19 inch rekmontage

Type achterzijde: 6 U VME64

Gegevensoverdracht: VME64; VME2eSST

Vermogen per sleuf: 30W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Voor naar links

Rekhoogte: 4U

Type voeding: Open frame

Voeding inbegrepen: Ja

I/O achter: Nee

Voldoet aan: ANSI/VITA 1.1-1994

Diepte: 277.5mm

Hoogte: 177mm

Breedte: 449mm

Voeding: 350W

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE