


# Front Panel Kit, Shielded, Bottom Hinged, 3 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

## CATALOGUSNUMMER

**20848-601**

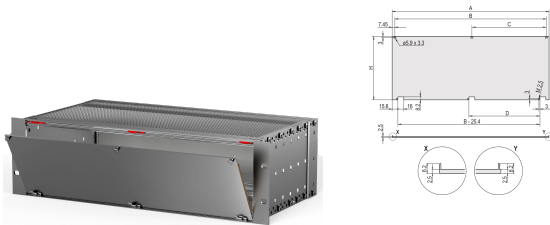

U-profile front panel bottom hinged for textile gasket.

## CERTIFICERINGEN



## KENMERKEN

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

## PRODUCTKENMERKEN

Rekhoogte: 3U

Type accessoire: Frontpaneel

Rekbreedte: 84HP

Hoeveelheid in verpakking: 1

Montage: Scharnierend, onderkant

Type EMC-pakking: Textiel

Afwerking voorzijde: Geanodiseerd

Afwerking achterzijde: Geleidend

Behandelde randen: Nee

Voldoet aan: IEC 60297-3-101; IEEE 1101,1/10

Diepte (D): 2.5mm

EMC-afscherming: Nee (achteraf te monteren)

Afwerking: Geanodiseerd; Geëloxeerd

Hoogte (H): 128.4mm

Materiaal: Aluminium

Producttype: Frontpaneel


Type: Frontpaneel zonder handgreep

Breedte (W): 426.4mm

## AANVULLENDE PRODUCTGEGEVENS

Front panel can be removed in opened position ( $> 135^\circ$ ).

## DIAGRAMMEN

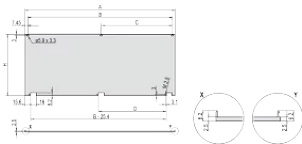

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**