


Airbender, inzetstuk kaartgeleider, 70P-blokkering, 4HP, 160 mm, 10-delige set

CATALOGUSNUMMER

24563-040

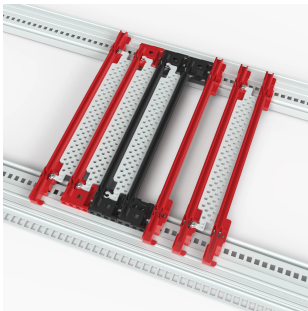

The nVent SCHROFF AirBender Inlay enhances cooling efficiency by up to 85% per slot by balancing airflow in mixed impedance environments. It is easy to install, reduces fan noise, and improves overall system performance.

KENMERKEN

AirBender card guide inserts enhance cooling efficiency in electronic systems by up to 85% per 4HP slot by balancing airflow in environments with mixed air impedances

70% blockage: The AirBender introduces additional air impedance in slots with less critical components, redirecting airflow to more vulnerable zones and ensuring better cooling outcomes for all cards

Easy installation: Simply clip the AirBender into nVent SCHROFF plastic card guides and optionally secure it with a screw

Favors reduced noise development from the fans by maintaining them at an efficient operating point

Air bender and CassettePRO cannot be used together in the same slot.

PRODUCTKENMERKEN

Producttype: Luchtkeerschot

Productserie: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

Werkt met: Subracks; Omkastingen; Systemen

Rekbreedte: 4HP

Diepte: 160mm

Materiaal: Polycarbonaat

Hoeveelheid in verpakking: 10

Kleur: Grijs

Voldoet aan: EN 45545-2; UL® 94V-0

AANVULLENDE PRODUCTGEGEVENS

AirBenders with different blockage levels available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE