


CPCI-systeem met insteekbare voedingseenheid, PSB H.110, 4 u, 8 sleuven

CATALOGUSNUMMER

24579-135

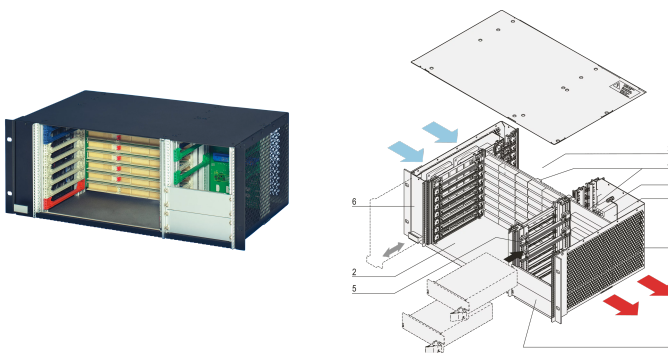

4 U CompactPCI System with PSB and H.110, with horizontal Card Cage for eight 6 U Boards, eighth RTM Boards and two CompactPCI 3 U Pluggable Power Supplies. Option to build in up to four pluggable Power Supplies.

CERTIFICERINGEN



KENMERKEN

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.16

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Monolithic backplane for (signals and power) 64-bit CompactPCI; PSB (Package Switched Backplane), PICMG 2.16; H.110, 8 slot, 6 U, 64 bit CompactPCI (2 fabric/switch slots, 6 node slots H.110), system slot left; Integrated power backplane with 2 x P 47 connectors

Heat dissipation by hot-swap fan unit, airflow left to right

Prepared to accept two 19" CompactPCI PSUs 250 W (3 U, 8 HP)

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 8

Type: 19 inch rekmontage

Type achterzijde: 6 U CompactPCI met PSB en H.110

Gegevensoverdracht: 64-bits PCI-bus; GbE

Vermogen per sleuf: 40W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Links naar rechts

Rekhoogte: 4U

Type voeding: (2) Insteekbare voeding

Voeding inbegrepen: Nee

I/O achter: Ja

Voldoet aan: PICMG 2,0 R3.0

Diepte: 275mm

Hoogte: 177mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE