


CPCI System With Pluggable PSU, Desktop, 4 U, 8 Slot, 44 HP

CATALOGUSNUMMER

24579-604

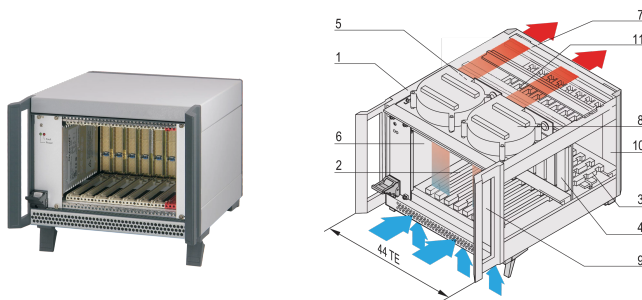

CompactPCI Desktop Chassis with vertical Card Cage for eight 3 U Boards, eight 3 U RTM Boards and one CompactPCI 3 U Pluggable Power Supply.

CERTIFICERINGEN



KENMERKEN

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with vertical card cage. Board format Front: 3 U, 160 mm deep; Rear I/O: 3 U, 80 mm deep

Backplane 8 slot, 3 U, 32 bit, system slot right; 8 HP wide CPU can be used

Heat dissipation by two radial fans, airflow front to rear

19" PSU, 300 W, 3 U, 8 HP

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 8

Type: Desktop

Type achterzijde: 3 U CompactPCI

Gegevensoverdracht: 32-bits PCI-bus

Vermogen per sleuf: 30W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Voor naar achter

Rekhoogte: 4U

Type voeding: (1) Insteekbare voeding

Voeding inbegrepen: Ja

I/O achter: Ja

Voldoet aan: PICMG 2,0 R3.0

Diepte: 275mm

Hoogte: 177mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE