


Frame Type Plug-In Unit Guide Rail, 5 Pairs

CATALOGUSNUMMER

24812-101

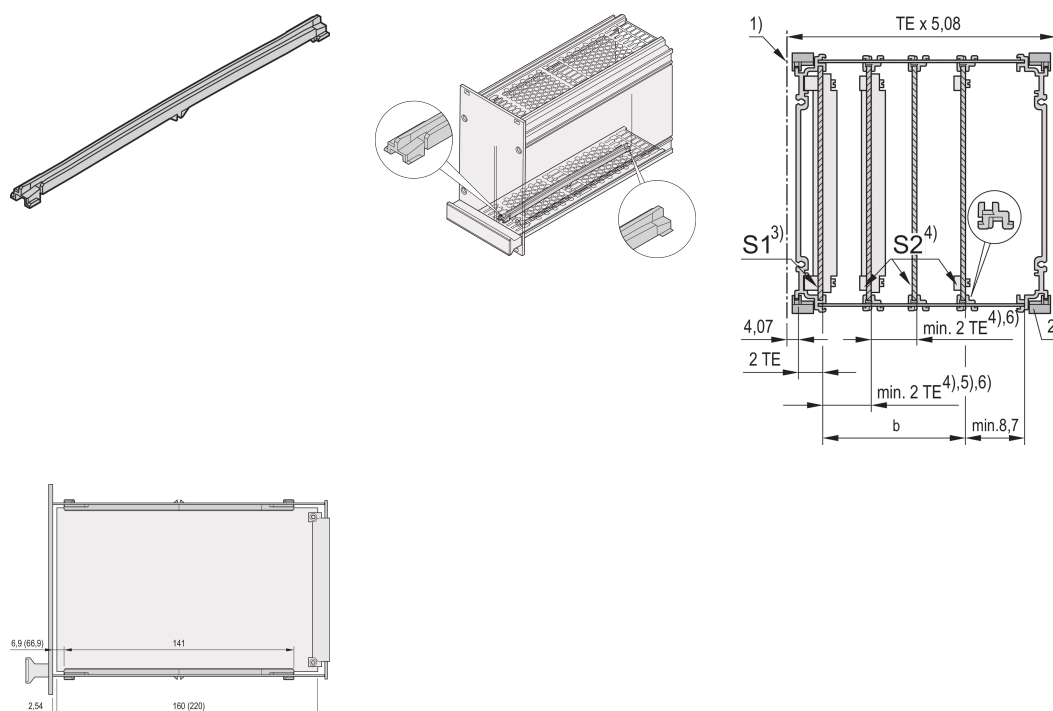

The guide rails can be clipped onto the perforated top / bottom cover. It is required if the PCB will be assembled from Slot 2.

CERTIFICERINGEN



KENMERKEN

PCB fixing required from slot 2

Groove width 2 mm

PBT, UL, 94, V-0

Red

PRODUCTKENMERKEN

Producttype: Geleiderail

Type: Plug-in-eenheid frametype

Werkt met: Plug-in-eenheid frametype

Diepte plaat: 160mm

Groefbreedte: 2

Materiaal: Polycarbonaat

Kleur: Rood


Hoeveelheid in verpakking: 10

Verpakkingseenheid: Paar

AANVULLENDE PRODUCTGEGEVENS

Guide rail fit to 167 mm and 227 deep cassettes.

DIAGRAMMEN

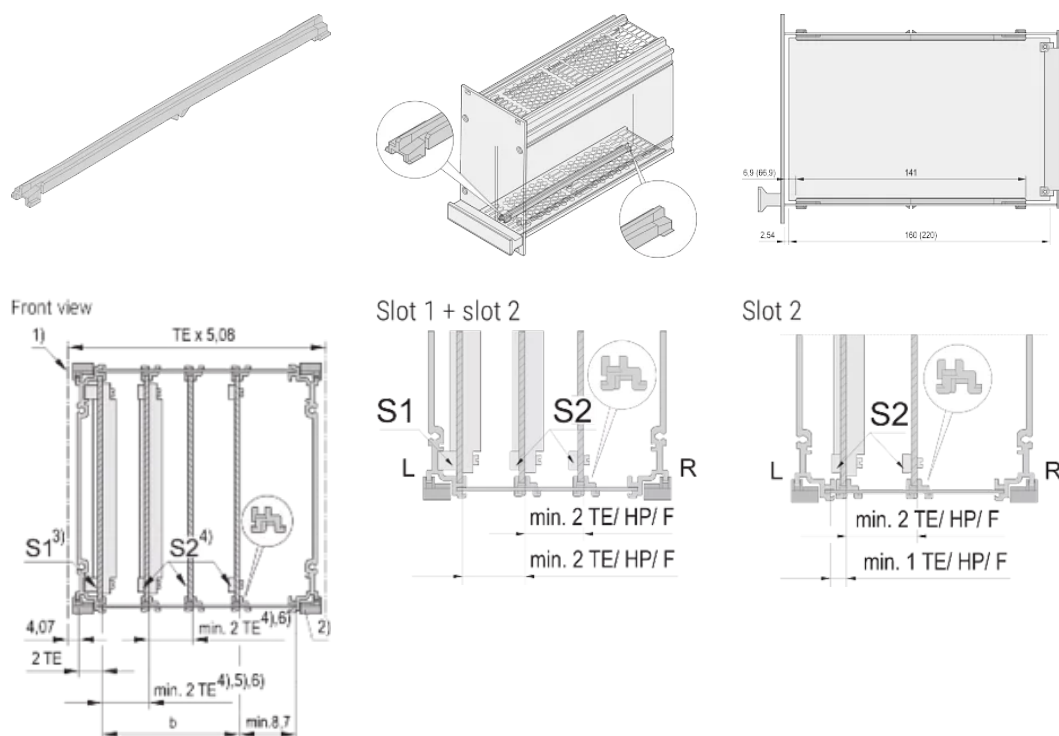

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE