

Frame Type Plug-In Unit PRO Kit, Unshielded, Perforated, Multiple Connectors, 3 U, 12 HP, 227 mm

CATALOGUSNUMMER

24812-362



Frame type plug-in unit, non-shielded, perforated top / bottom cover, rear panel with cutout for more connectors.



KENMERKEN

Cover plate with perforation, for guide rails (airflow approx. 60 %)

Extruded side panels right and left, with grooves for insertion of a printed circuit board (standard board position is on the left only)

Rear panel with cut-outs for multiple connectors

PRODUCTKENMERKEN

Rekhoogte: 3U

Rekbreedte: 12HP

Diepte (D): 227mm

Type handgreep: Trapezium

Hoeveelheid in verpakking: 1

Type achterpaneel: Uitsparing voor meerdere connectoren

Type afdekplaat: Afdekplaat met perforatie voor geleiderails

Afwerking voorzijde: Geanodiseerd

Afwerking achterzijde: Geanodiseerd

Koeling: Geperforeerd

EMC-afscherming: Nee

Afwerking: Geanodiseerd

Materiaal: Aluminium

Producttype: Cassette


Type: PRO-insteekeenheden frame-type

AANVULLENDE PRODUCTGEGEVENS

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

Please order guide rails separately.

DIAGRAMMEN

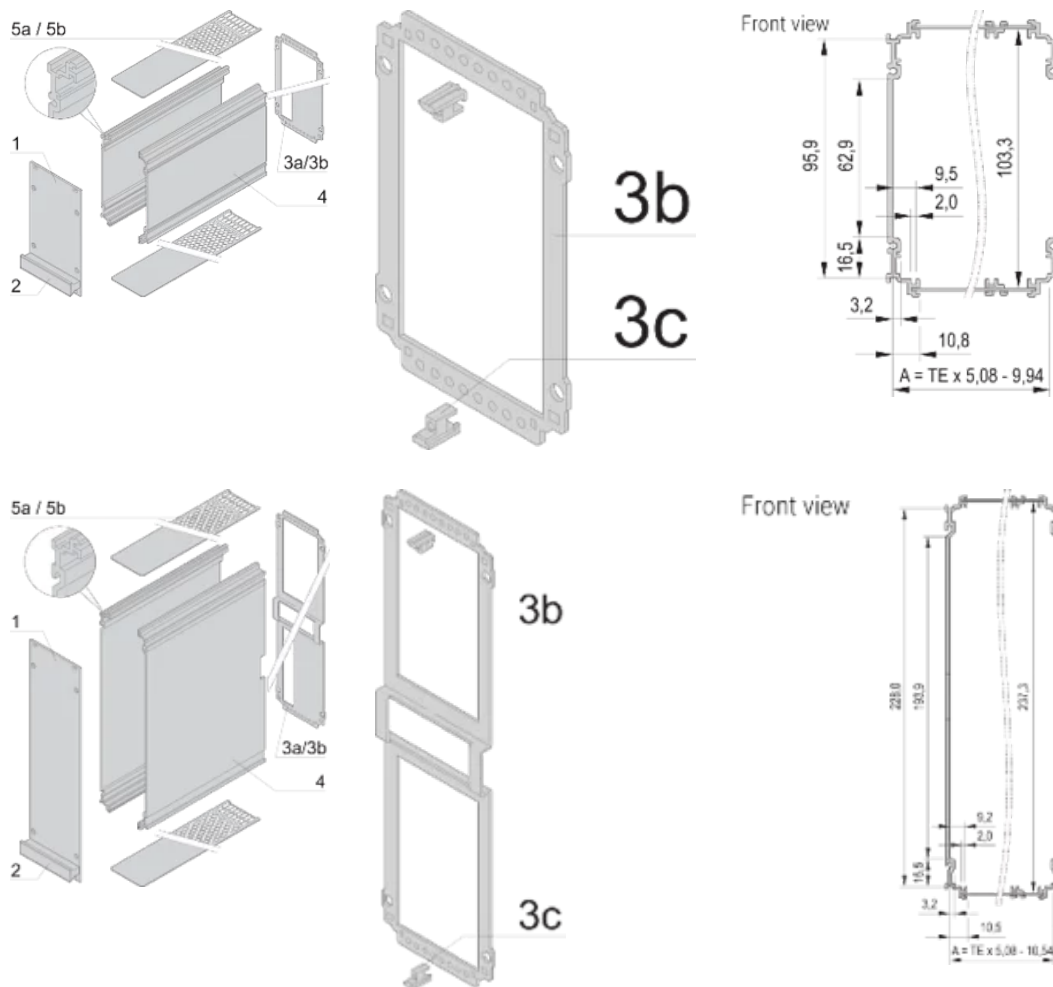

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE