


Front Panel EMC Stainless Steel Shielding Kit, for U-Shaped front panels

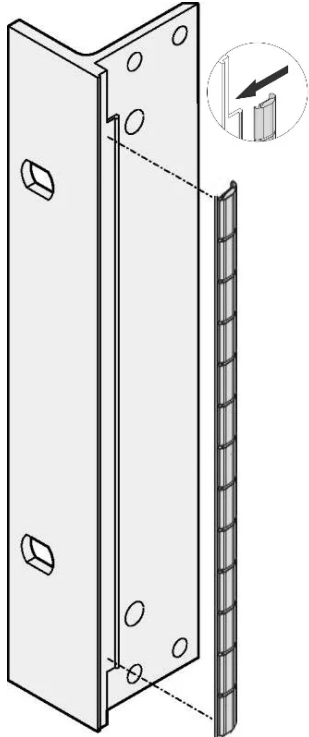

The stainless EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels.

The gasket will be clipped onto the right front panel bracket, the 19" bracket or rear profile of the subrack

KENMERKEN

The stainless steel EMC-gasket for SCHROFF U-shaped front panels, offers excellent performance in shielding effectiveness and an enormous temperature range from -200 to +160°C.

Easy mounting by clipping the gasket onto the right front panel bracket, the 19" bracket or rear profile of the subrack

Temperature range from -200 to +160°C.

SPECIFICATIES

Werkt met:	Subracks; Omkastingen; Frontpanelen
Productserie:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Plug-in-eenheid frametype
Producttype:	Afschermingsset
Materiaal:	Roestvrij staal


Table 1/1

Catalogusnummer	Rekhoogte	Hoeveelheid in verpakking	Rekbreedte	Snelle verzending
21102-115	2U	10	10HP	Nee
21102-105	3U	10		Nee
21102-106	3U	100	100HP	Nee
21102-113	4U	10	10HP	Nee
21102-117	5U	10	10HP	Nee
21102-107	6U	10	10HP	Nee
21102-108	6U	100	100HP	Nee
21102-109	9U	10	10HP	Nee

AANVULLENDE PRODUCTGEGEVENS

EMC gaskets (stainless) are required for shielding the front panels.

DIAGRAMMEN

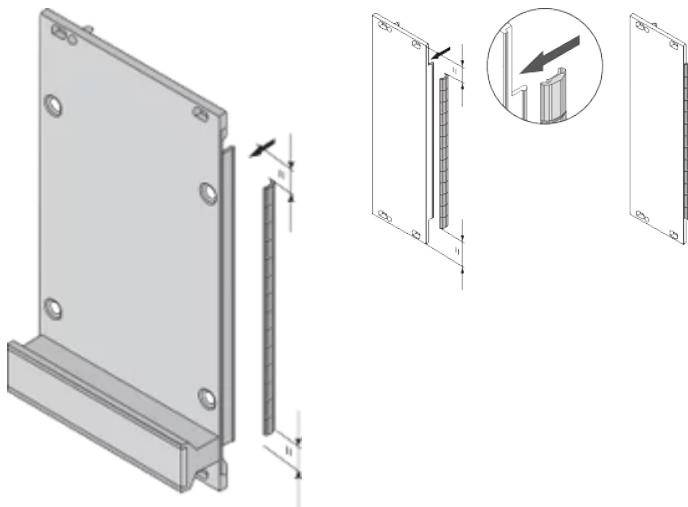

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent

klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE