

Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts



Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICERINGEN



KENMERKEN

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

SPECIFICATIES

Rekhoogte:	3U
Rekbreedte:	4HP
Materiaal:	Aluminium
Afwerking:	Geanodiseerd; Geëloxeerd
Type accessoire:	Frontpaneel
Producttype:	Frontpaneel

Type: Frontpaneel zonder handgreep

EMC-afscherming: Nee (achteraf te monteren)

Table 1/2

Catalogusnummer	Hoeveelheid in verpakking	Montage	Type EMC-pakking	Afwerking voorzijde	Afwerking achterzijde	Aantal pennen
30118-348	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(1) 9
30118-349	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(1) 15
30118-350	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(1) 25
30118-351	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(2) 9
30118-352	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(2) 15
30118-353	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(2) 25
30118-354	1	Opschroefbare voorzijde	Roestvrij staal	Geanodiseerd	Geleidend	(3) 9

Table 2/2

Catalogusnummer	Behandelde randen	Voldoet aan	Diepte (D)	Hoogte (H)	Breedte (W)	Snelle verzending
30118-348	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee
30118-349	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee
30118-350	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee
30118-351	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee
30118-352	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee
30118-353	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee

Catalogusnummer	Behandelde randen	Voldoet aan	Diepte (D)	Hoogte (H)	Breedte (W)	Snelle verzending
30118-354	Nee	IEC 60297-3-101, IEEE 1101,1/10	2.5mm	128.4mm	19.98mm	Nee

AANVULLENDE PRODUCTGEGEVENS


Please order fixing material (sleeves, collar screws) separately.





Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMMEN

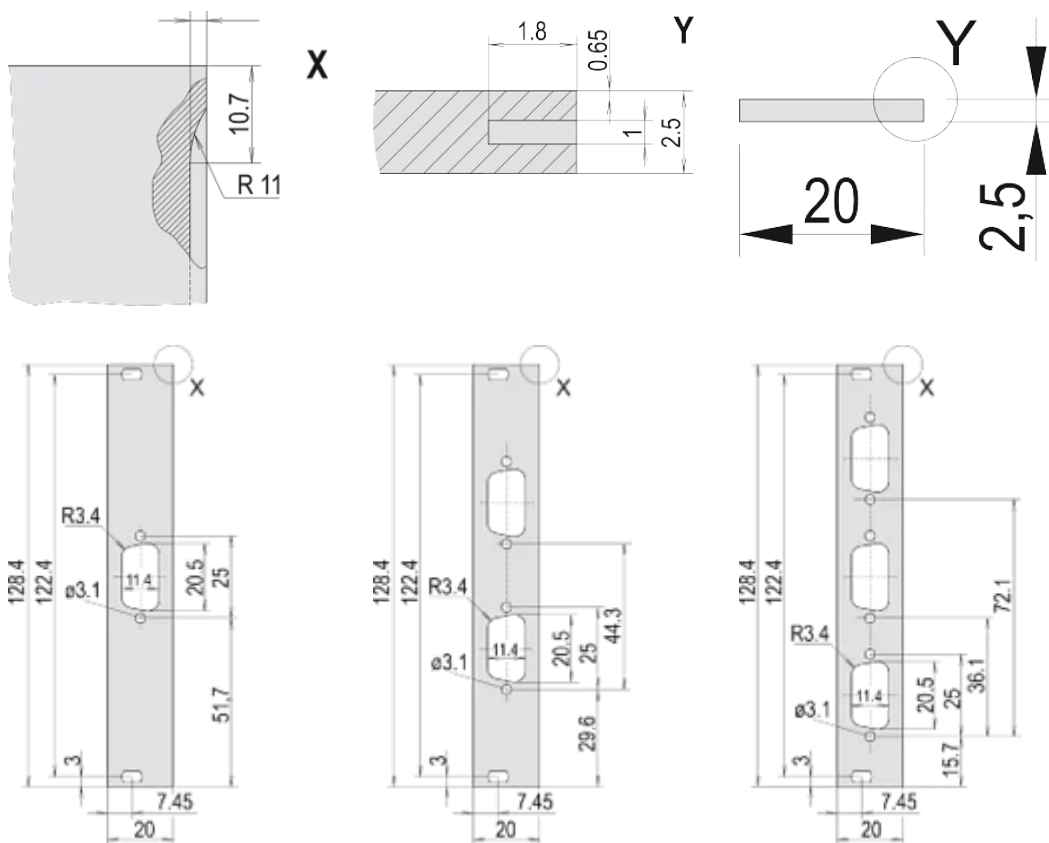

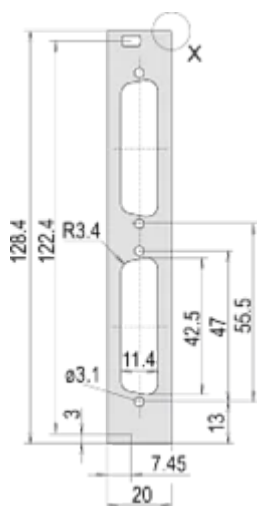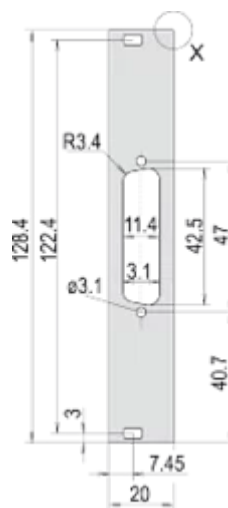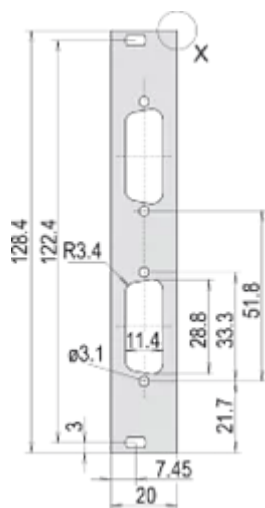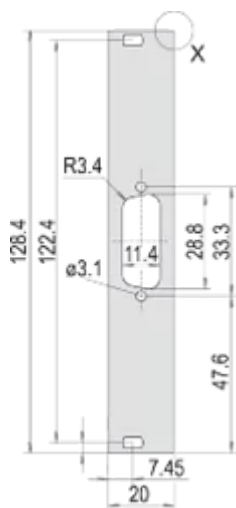

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE