


Front Panel, U-shaped, Screwless Mounting for RatiopacPRO Style, Retrofit Shielding

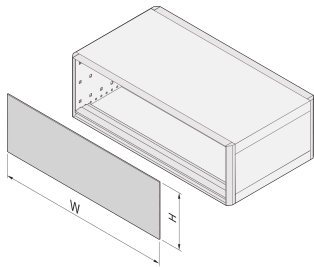

Front panel screwless, front side: anodized, rear side: conductive; unshielded

CERTIFICERINGEN



KENMERKEN

Front panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables screwless mounting on horizontal rails

SPECIFICATIES

Materiaal:	Aluminium
Afwerking:	Geanodiseerd; Geëloxeerd
Werkt met:	Omkastingen
Producttype:	Frontpaneel
Type:	Frontpaneel
Productserie:	RatiopacPRO-stijl; RatiopacPRO

Table 1/1

Catalogusnummer	Rekhoogte	Rekbreedte	Hoeveelheid in verpakking	Hoogte	Breedte	Snelle verzending
34572-199	2U	28HP	1	84mm	141.9mm	Nee

Catalogusnummer	Rekhoogte	Rekbreedte	Hoeveelheid in verpakking	Hoogte	Breedte	Snelle verzending
34572-200	2U	42HP	1	84mm	213.2mm	Nee
34572-201	2U	63HP	1	84mm	319.7mm	Nee
34572-202	2U	84HP	1	84mm	426.4mm	Nee
34572-203	3U	28HP	1	128.4mm	141.9mm	Nee
34572-204	3U	42HP	1	128.4mm	213.2mm	Nee
34572-205	3U	63HP	1	128.4mm	319.7mm	Nee
34572-206	3U	84HP	1	128.4mm	426.4mm	Nee
34572-207	4U	28HP	1	172.9mm	141.9mm	Nee
34572-208	4U	42HP	1	172.9mm	213.2mm	Nee
34572-209	4U	63HP	1	172.9mm	319.7mm	Nee
34572-210	4U	84HP	1	172.9mm	426.4mm	Nee
34572-223	6U	28HP	1	261.8mm	141.9mm	Nee
34572-224	6U	42HP	1	261.8mm	213.2mm	Nee
34572-225	6U	63HP	1	261.8mm	319.7mm	Nee
34572-226	6U	84HP	1	261.8mm	426.4mm	Nee

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE