


Guide Rail With Coding, preassembled ESD Clip for CompactPCI/ VME64x, PC

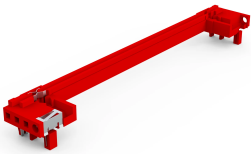

CERTIFICERINGEN



KENMERKEN

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPECIFICATIES

Werkt met:	Subracks; Omkastingen; 19 inch chassis; Systemen
Type:	Codering en voorgemonteerde ESD-klemmen
Productserie:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Materiaal:	Vezelversterkt kunststof
Producttype:	Geleiderail

Table 1/2

Catalogusnummer	Kleur	Hoeveelheid in verpakking	Diepte plaat	Groefbreedte	Voldoet aan	Railtype
24568-847	Rood	10	160mm	2	EN 45545-2	Onderkant
24568-848	Grijs	10	160mm	2	EN 45545-2	Onderkant
24568-850	Rood	10	160mm	2	EN 45545-2	Bovenkant
24568-851	Grijs	10	160mm	2	EN 45545-2	Bovenkant
24568-853	Rood	10	70mm	2	EN 45545-2	Bovenkant
24568-854	Grijs	10	70mm	2	EN 45545-2	Bovenkant
24568-855	Rood	10	70mm	2	EN 45545-2	Onderkant
24568-856	Grijs	10	70mm	2	EN 45545-2	Onderkant

Table 2/2

Catalogusnummer	Snelle verzending
24568-847	Nee
24568-848	Nee
24568-850	Nee
24568-851	Nee
24568-853	Nee
24568-854	Nee
24568-855	Nee
24568-856	Nee

AANVULLENDE PRODUCTGEGEVENS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE