

Static Handle Plastic in Trapezoid Form, Black



The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

CERTIFICERINGEN



KENMERKEN

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFICATIES

Werkt met:	Frontpanelen
Producttype:	Greep
Materiaal:	Polycarbonaat
Type:	Statisch

Table 1/2

Catalogusnummer	Rekbreedte	Hoeveelheid in verpakking	Type handgreep	Ontvlambaarheidsklasse	Kleur	Voldoet aan
20808-080	5HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-081	6HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-082	7HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-083	8HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-084	9HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-085	10HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-086	12HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-087	14HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-088	21HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-089	28HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-090	40HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Catalogusnummer	Rekbreedte	Hoeveelheid in verpakking	Typehandgreep	Ontvlambaarheidsklasse	Kleur	Voldoet aan
20808-091	42HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-396	3HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-397	4HP	1	Trapezium, statisch	UL® 94V-0	Zwart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Table 2/2

Catalogusnummer	Breedte (W)	Snelle verzending
20808-080	24mm	Nee
20808-081	29mm	Nee
20808-082	34.1mm	Nee
20808-083	39.2mm	Nee
20808-084	44.3mm	Nee
20808-085	49.4mm	Nee
20808-086	59.6mm	Nee
20808-087	69.7mm	Nee
20808-088	105.2mm	Nee
20808-089	140.8mm	Nee
20808-090	201.8mm	Nee
20808-091	212mm	Nee


Catalogusnummer	Breedte (W)	Snelle verzending
20809-396	13.8mm	Nee
20809-397	18.9mm	Nee

AANVULLENDE PRODUCTGEGEVENS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMMEN

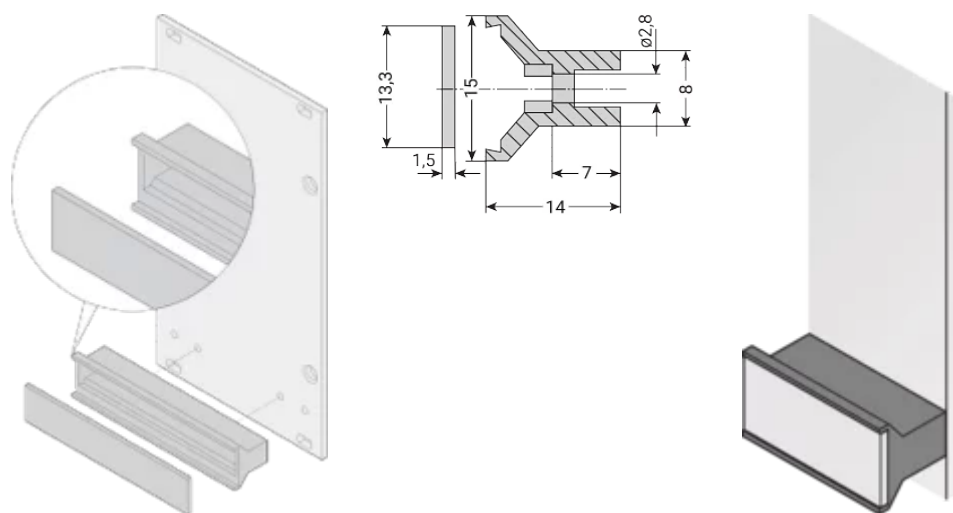

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE