


U-profile Front Panel, Shieldable, D-Sub Cutouts

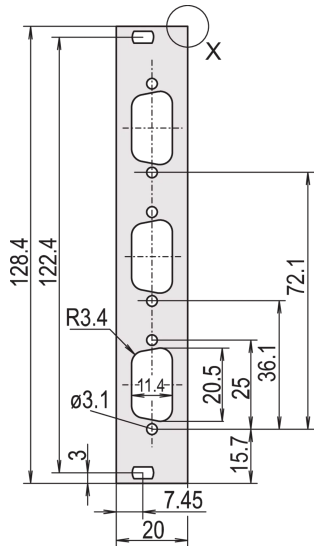

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICERINGEN



KENMERKEN

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFICATIES

Diepte (D):	2.5mm
Rekhoogte:	3U
Rekbreedte:	4HP
Materiaal:	Aluminium
Afwerking:	Geanodiseerd; Geëloxeerd
Type accessoire:	Frontpaneel
Producttype:	Frontpaneel
Type:	Frontpaneel zonder handgreep

EMC-afscherming: Nee (achteraf te monteren)

Table 1/2

Catalogusnummer	Hoeveelheid in verpakking	Montage	Type EMC-pakking	Afwerking voorzijde	Afwerking achterzijde	Aantal pennen
30849-749	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(1) 9
30849-750	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(2) 9
30849-751	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(3) 9
30849-752	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(1) 15
30849-753	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(2) 15
30849-754	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(1) 25
30849-755	1	Opschroefbare voorzijde	Textiel	Geanodiseerd	Geleidend	(2) 25

Table 2/2

Catalogusnummer	Behandelde randen	Voldoet aan	Hoogte (H)	Breedte (W)	Snelle verzending
30849-749	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-750	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-751	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-752	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-753	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-754	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee
30849-755	Nee	IEC 60297-3-101, IEEE 1101,1/10	128.4mm	20mm	Nee

AANVULLENDE PRODUCTGEGEVENS


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMMEN

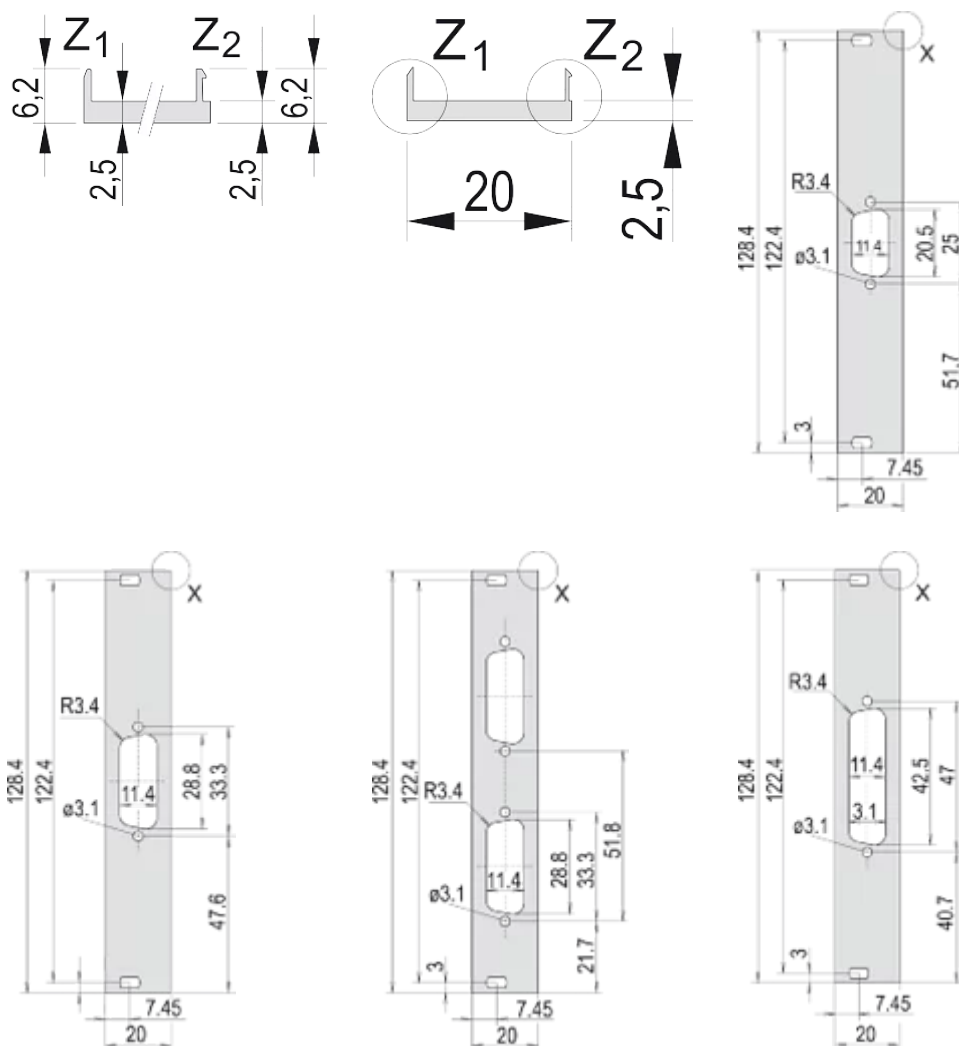

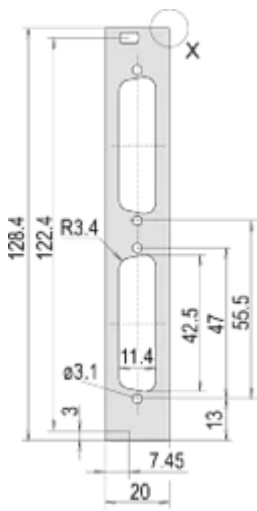

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE