

Hydraulische flexibele/niet-flexibele rail werkplaats, 230 V



CERTIFICERINGEN



KENMERKEN

Mobile workbench for cutting, bending and punching copper busbars or nVent ERIFLEX Flexibar

Includes hydraulic punch, hydraulic busbar cutter, hydraulic bender with programmable angle controller, hydraulic pump with foot controller, calibrated gauge and stop, and two ejection stops

Large stainless steel work surface with collapsible extensions support large copper busbars or nVent ERIFLEX Flexibar

Built-in storage cabinet with lockable door and four drawers for storing accessories

Four-way directional valve makes it possible to quickly switch between tools without disconnecting and reconnecting tools

Includes an additional hydraulic hose and 6 m (19.69') power cord to connect an additional hydraulic tool

Scrap storage bins under work surface

Forklift rail, locking directional wheels and built-in handles provide easy mobility

Protected by an electrical panel control with circuit breaker

SPECIFICATIES


Table 1/2

Catalogusnummer	Artikelnummer	Hoogte (H)	Lengte (L)	Breedte (W)	A	Voedingsspanning
HYDR-WC-230V	545650	1465 mm	1465mm	770 mm	1380 mm	230

Table 2/2

Catalogusnummer	Artikelnummer	Gewicht van de eenheid
HYDR-WC-230V	545650	356 kg

DIAGRAMMEN

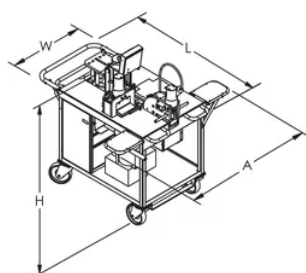

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische

ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE