

# Hoekig gietbassin, vullen met bovenkant, 45°



Top fill pouring basins should be used on angular installations whenever the clearances of the structure allow. The compact size of the top fill pouring basins help ensure the best possible flow of filler material.

## KENMERKEN

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

## SPECIFICATIES

**Materiaal:** Grafiet

Table 1/2

| Catalogusnummer | Diameter (Ø) | Lengte 1 (L1) | Lengte 2 (L2) | Breedte (W) | Hoogte 1 (H1) | Hoogte 2 (H2) |
|-----------------|--------------|---------------|---------------|-------------|---------------|---------------|
| RBWS1537M       | 95 mm        | 162 mm        | 14 mm         | 76 mm       | 10mm          | 89mm          |
| RBWS1537F       | 64 mm        | 162 mm        | 14 mm         | 76 mm       | 10mm          | 89mm          |
| RBWS1537C       | 48 mm        | 162 mm        | 14 mm         | 76 mm       | 10mm          | 89mm          |

Table 2/2

| Catalogusnummer | Hoek (a) |
|-----------------|----------|
| RBWS1537M       | 45 °     |

| Catalogusnummer | Hoek (a) |
|-----------------|----------|
| RBWS1537F       | 45 °     |
| RBWS1537C       | 45 °     |


## AANVULLENDE PRODUCTGEGEVENS

RBWS1537 pouring basins require one RBM2660 pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMMEN

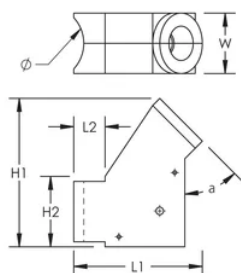

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

**Noord-Amerika**

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische  
ondersteuning

**Europa**

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

**Europa**

Duitsland:

800 1890272

andere landen:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**