

ELFB Taper Form Bolt



The ELFB taper bolt is used to firmly attach a nVent LENTON taper-threaded coupler onto formwork in precast and cast-in-place construction. This reusable form saving accessory allows forms to be pre-drilled with the correct spacing of the reinforcing steel, which speeds construction and allows the forms to be re-used on repetitive construction elements. This system can be used in conjunction with coupler boxes to eliminate the use of bend-out-boxes and also helps eliminate protruding dowel bars.

The screw-in bolt is designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour. The bolt eliminates the need for form saving plates and simplifies the use of standard couplers in form saving applications.

KENMERKEN

Multiple lengths available depending on form thickness

Used in both form saving and coupler box applications

Bar end protector included to protect the nVent LENTON taper thread

Durable, re-usable and long lasting

Saves time and money

SPECIFICATIES

Materiaal: Staal

Table 1/2

Catalogusnummer	Moer inbegrepen	Vormdikte (FT)	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte (L)
ELFB10X003	Nee	3 mm	10 mm	#3		21mm
ELFB12X003	Nee	3 mm	12 mm	#4	10M	21mm
ELFB10X020	Ja	3 - 20 mm	10 mm	#3		55mm

Catalogusnummer	Moer inbegrepen	Vormdikte (FT)	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte (L)
ELFB12X010	Nee	3 - 10 mm	12 mm	#4	10M	28mm
ELFB14X003	Nee	3 mm	14 mm			25mm
ELFB10X040	Ja	3 - 40 mm	10 mm	#3		75mm
ELFB12X020	Ja	3 - 20 mm	12 mm	#4	10M	60mm
ELFB16X003	Nee	3 mm	16 mm	#5	15M	28mm
ELFB18X003	Nee	3 mm	18 mm			33mm
ELFB20X003	Nee	3 mm	20 mm	#6	20M	38mm
ELFB22X003	Nee	3 mm	22 mm	#7		40mm
ELFB25X003	Nee	3 mm	25 mm	#8	25M	43mm
ELFB28X003	Nee	3 mm	28 mm	#9	30M	45mm
ELFB30X003	Nee	3 mm	30 mm			55mm
ELFB32X003	Nee	3 mm	32 mm	#10		49mm
ELFB34X003	Nee	3 mm	34 mm			59mm
ELFB36X003	Nee	3 mm	36 mm	#11	35M	56mm
ELFB16X010	Nee	3 - 10 mm	16 mm	#5	15M	35mm
ELFB20X010	Nee	3 - 10 mm	20 mm	#6	20M	45mm
ELFB14X020	Ja	3 - 20 mm	14 mm			65mm
ELFB16X020	Ja	3 - 20 mm	16 mm	#5	15M	70mm

Catalogusnummer	Moer inbegrepen	Vormdikte (FT)	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte (L)
ELFB18X020	Ja	3 - 20 mm	18 mm			75mm
ELFB20X020	Ja	3 - 20 mm	20 mm	#6	20M	90mm
ELFB22X020	Ja	3 - 20 mm	22 mm	#7		90mm
ELFB25X020	Ja	3 - 20 mm	25 mm	#8	25M	100mm
ELFB28X020	Ja	3 - 20 mm	28 mm	#9	30M	100mm
ELFB30X020	Ja	3 - 20 mm	30 mm			110mm
ELFB32X020	Ja	3 - 20 mm	32 mm	#10		110mm
ELFB34X020	Ja	3 - 20 mm	34 mm			120mm
ELFB36X020	Ja	3 - 20 mm	36 mm	#11	35M	115mm
ELFB12X040	Ja	3 - 40 mm	12 mm	#4	10M	80mm
ELFB14X040	Ja	3 - 40 mm	14 mm			85mm
ELFB16X040	Ja	3 - 40 mm	16 mm	#5	15M	90mm
ELFB18X040	Ja	3 - 40 mm	18 mm			95mm
ELFB20X040	Ja	3 - 40 mm	20 mm	#6	20M	105mm
ELFB22X040	Ja	3 - 40 mm	22 mm	#7		110mm
ELFB25X040	Ja	3 - 40 mm	25 mm	#8	25M	115mm
ELFB28X040	Ja	3 - 40 mm	28 mm	#9	30M	120mm
ELFB30X040	Ja	3 - 40 mm	30 mm			130mm

Catalogusnummer	Moer inbegrepen	Vormdikte (FT)	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte (L)
ELFB32X040	Ja	3 - 40 mm	32 mm	#10		130mm
ELFB34X040	Ja	3 - 40 mm	34 mm			140mm
ELFB36X040	Ja	3 - 40 mm	36 mm	#11	35M	135mm

Table 2/2				
Catalogusnummer	Buitendiameter (OD)	Breedte fitting (SW)	Gewicht eenheid	Aantal onderleggringen
ELFB10X003	12 mm	18mm	0.04 kg	2
ELFB12X003	14 mm	21mm	0.06 kg	2
ELFB10X020	12 mm	18mm	0.08 kg	1
ELFB12X010	14 mm	21mm	0.08 kg	4
ELFB14X003	16 mm	24mm	0.09 kg	2
ELFB10X040	12 mm	18mm	0.1 kg	1
ELFB12X020	14 mm	21mm	0.12 kg	1
ELFB16X003	20 mm	30mm	0.14 kg	2
ELFB18X003	20 mm	30mm	0.17 kg	2
ELFB20X003	24 mm	36mm	0.27 kg	2
ELFB22X003	24 mm	36mm	0.29 kg	2
ELFB25X003	30 mm	46mm	0.52 kg	2
ELFB28X003	30 mm	46mm	0.55 kg	2
ELFB30X003	30 mm	46mm	0.71 kg	4

Catalogusnummer	Buitendiameter (OD)	Breedte fitting (SW)	Gewicht eenheid	Aantal onderleggringen
ELFB32X003	36 mm	55mm	0.92 kg	2
ELFB34X003	36 mm	55mm	1.16 kg	4
ELFB36X003	36 mm	55mm	1 kg	2
ELFB16X010	20 mm	30mm	0.2 kg	4
ELFB20X010	24 mm	36mm	0.36 kg	4
ELFB14X020	16 mm	24mm	0.17 kg	1
ELFB16X020	20 mm	30mm	0.3 kg	1
ELFB18X020	20 mm	30mm	0.32 kg	1
ELFB20X020	24 mm	36mm	0.54 kg	1
ELFB22X020	24 mm	36mm	0.55 kg	1
ELFB25X020	30 mm	46mm	1 kg	1
ELFB28X020	30 mm	46mm	1.06 kg	1
ELFB30X020	30 mm	46mm	1.11 kg	1
ELFB32X020	36 mm	55mm	1.73 kg	1
ELFB34X020	36 mm	55mm	1.81 kg	1
ELFB36X020	36 mm	55mm	1.81 kg	1
ELFB12X040	14 mm	21mm	0.14 kg	1
ELFB14X040	16 mm	24mm	0.2 kg	1


Catalogusnummer	Buitendiameter (OD)	Breedte fitting (SW)	Gewicht eenheid	Aantal onderleggingen
ELFB16X040	20 mm	30mm	0.34 kg	1
ELFB18X040	20 mm	30mm	0.36 kg	1
ELFB20X040	24 mm	36mm	0.58 kg	1
ELFB22X040	24 mm	36mm	0.62 kg	1
ELFB25X040	30 mm	46mm	1.09 kg	1
ELFB28X040	30 mm	46mm	1.16 kg	1
ELFB30X040	30 mm	46mm	1.21 kg	1
ELFB32X040	36 mm	55mm	1.87 kg	1
ELFB34X040	36 mm	55mm	1.95 kg	1
ELFB36X040	36 mm	55mm	1.95 kg	1

AANVULLENDE PRODUCTGEGEVENS

Length dimension is for reference only.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMEN

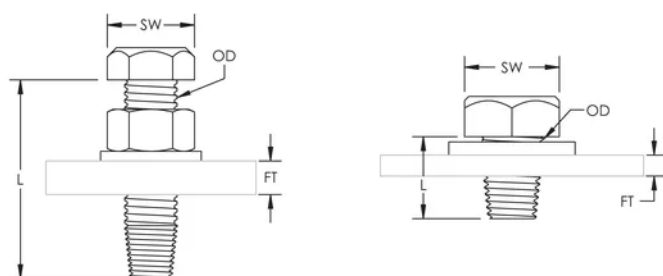

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221
optie 1 – Klantenservice
optie 2 – Technische
ondersteuning

Europa

Nederland:
+31 800-0200135
Frankrijk:
+33 800 901 793

Europa

Duitsland:
800 1890272
andere landen:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE