

T-Series Horizontal Fixed Angle Splice Kit, Top Fill, 45-75°



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

KENMERKEN

Simplifies ordering

Used to splice the same diameter bars

SPECIFICATIES

Huls: Standaardlengte

Table 1/2

Catalogusnummer	Hoek (a)	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte 1 (L1)	Lengte 2 (L2)
RBT189175H	75 °	57 mm	#18	55M	129 mm	390 mm
RBT189145H	45 °	57 mm	#18	55M	180 mm	268 mm

Table 2/2

Catalogusnummer	Hoogte 1 (H1)	Hoogte 2 (H2)	Diameter (Ø)
RBT189175H	576mm	253mm	178 mm
RBT189145H	601mm	225mm	178 mm

AANVULLENDE PRODUCTGEGEVENS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

Splice Kit Components							
Splice Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube	Sleeve	Pouring Basin	Pouring Basin Crucible
RBT189145H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891HA	RBWS1537M	RBWS22777
RBT189175H	RBF270	RBS354720 RBS35479	RBS5037	RBS5039	RBT1891A	RBWS2224M	RBWS22777

DIAGRAMMEN

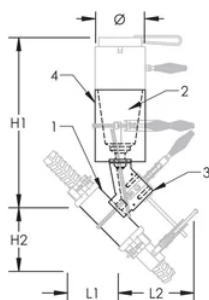

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische
ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE