

T-Series Horizontal Splice Kit, Side Fill



T-Series splice kits contain the following: Sleeve, filler material kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), pouring basin and pouring basin crucible. Splice kits are ordered based on the quantity of splices needed. Sleeves and filler material kits are one-time use parts. Pouring basins and crucibles are prorated based on their anticipated life. Ordering splice kits simplifies ordering, reduces order errors and helps ensure proper sizing of components. Kits can be ordered with longer (extended) sleeves for use when the reinforcing steel deformation pattern or spacing does not meet the minimum product specifications.

KENMERKEN

Simplifies ordering

Used to splice the same diameter bars

SPECIFICATIES

Huls: Standaardlengte

Table 1/2

Catalogusnummer	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Lengte 1 (L1)	Lengte 2 (L2)	Hoogte 1 (H1)
RBT8101HS	25 mm	#8	25M	84 mm	403 mm	464mm
RBT1891HS	57 mm	#18	55M	102 mm	423 mm	533mm
RBT11101HS	36 mm	#11	35M	94 mm	413 mm	502mm
RBT1091HS	32 mm	#10		88 mm	407 mm	502mm
RBT6101HS	20 mm	#6	20M	84 mm	397 mm	464mm
RBT9101HS	28 mm	#9	30M	88 mm	407 mm	464mm

Table 2/2

Catalogusnummer	Hoogte 2 (H2)	Diameter (Ø)
RBT8101HS	75mm	102 mm
RBT1891HS	75mm	178 mm
RBT11101HS	75mm	127 mm
RBT1091HS	75mm	127 mm
RBT6101HS	75mm	102 mm
RBT9101HS	75mm	102 mm

AANVULLENDE PRODUCTGEGEVENS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

All dimensions are for reference only.

Components can also be purchased separately: (1) Sleeve, (2) Filler Material Kit (filler material, packing, pouring basin ceramic insert and disk, pouring basin ceramic guide tube), (3) Pouring Basin, and (4) Pouring Basin Crucible.

Splice Kit Components							
Splice Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube	Sleeve	Pouring Basin	Pouring Basin Crucible
RBT6101HS	RBF50	RBS35477	RBS5037	RBS5038	RBT6101HSA	RBWS1547X	RBWS22774
RBT8101HS	RBF55	RBS354710	RBS5037	RBS5038	RBT8101HSA	RBWS1547C	RBWS22774
RBT9101HS	RBF80	RBS354711	RBS5037	RBS5038	RBT9101HSA	RBWS1547D	RBWS22774
RBT1091HS	RBF90	RBS354712	RBS5037	RBS5038	RBT1091HSA	RBWS1547E	RBWS22775
RBT11101HS	RBF105	RBS354712	RBS5037	RBS5038	RBT11101HSA	RBWS1547F	RBWS22775
RBT1891HS	RBF270	RBS354720	RBS5037	RBS5039	RBT1891HSA	RBWS1547M	RBWS22777

DIAGRAMMEN

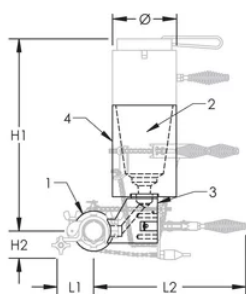

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische

ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE