

Kit met vulmateriaal voor horizontale overgang van de T-serie



T-Series horizontal filler material kits contain the following: Filler material, two horizontal packings, pouring basin ceramic guide tube and pouring basin crucible ceramic and disk. All filler material kits contain one-time use components that are sized to a specific sleeve, pouring basin and pouring basin crucible combination. Ordering filler material kits simplifies ordering, reduces order errors and helps ensure proper sizing of components.

KENMERKEN

Simplifies ordering

Used to splice different diameter bars

All components are for one-time use

SPECIFICATIES

Table 1/1

Catalogusnummer	Grootte rebar, metrisch	Formaat wapening, VS	Formaat rebar, Canada
RBT89101HB	28 mm, 25 mm	#9, #8	30M, 25M
RBT811101HB	36 mm, 25 mm	#11, #8	35M, 25M
RBT1118101HB	57 mm, 36 mm	#18, #11	55M, 35M
RBT1011101HB	36 mm, 32 mm	#11, #10	

AANVULLENDE PRODUCTGEGEVENS


Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Filler material kits are a component in splice kits. Care should be taken to avoid duplication of orders.

Components can also be purchased separately: (1) Filler Material, (2) Packing, (3) Pouring Basin Ceramic Guide Tube, and (4) Pouring Basin Ceramic Insert and Disk.

Filler Material Kit Components				
Filler Material Kit	Filler Material	Packing (2 Required)	Pouring Basin Ceramic Insert and Disk	Pouring Basin Ceramic Guide Tube
RBT89101HB	RBF90	RBS354711	RBS5037	RBS5038
RBT811101HB	RBF105	RBS354714	RBS5037	RBS5038
RBT1011101HB	RBF125	RBS354712	RBS5037	RBS5038
RBT1118101HB	RBF240	RBS354712	RBS5037	RBS5039

DIAGRAMMEN

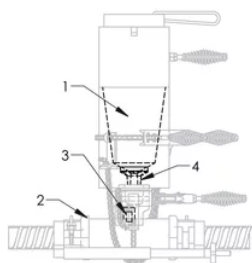

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221
optie 1 – Klantenservice
optie 2 – Technische
ondersteuning

Europa

Nederland:
+31 800-0200135
Frankrijk:
+33 800 901 793

Europa

Duitsland:
800 1890272
andere landen:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE