


T-Series Vertical Transition Sleeve

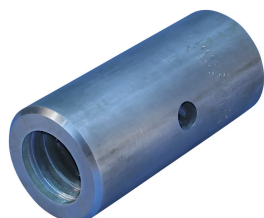

KENMERKEN

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice different diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

SPECIFICATIES

Afwerking:	Onbewerkt
Huls:	Standaardlengte
Materiaal:	Staal
100% Amerikaanse inhoud:	Ja

Table 1/2

Catalogusnummer	Wapeningsmaat, metrisch	Wapeningsmaat, VS	Wapeningsmaat, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Lengte 1 (L1)
RBT1114101A	43 mm, 36 mm	#14, #11	45M, 35M	70 mm	52 mm	152 mm
RBT1418101A	57 mm, 43 mm	#18, #14	55M, 45M	86 mm	67 mm	165 mm

Table 2/2

Catalogusnummer	Lengte 2 (L2)	Gewicht eenheid
-----------------	---------------	-----------------


RBT1114101A	76 mm	2.19 kg
RBT1418101A	76 mm	3.55 kg

AANVULLENDE PRODUCTGEGEVENS

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMEN

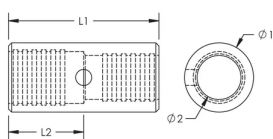

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221
optie 1 – Klantenservice
optie 2 – Technische
ondersteuning

Europa

Nederland:
+31 800-0200135
Frankrijk:
+33 800 901 793

Europa

Duitsland:
800 1890272
andere landen:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE