

Verticaal uitgietbassin, uitgeschoven



Extended vertical pouring basins are used when interferences of the structure are directly next to the tap hole in the sleeve.

KENMERKEN

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series vertical sleeves

SPECIFICATIES

Materiaal: Grafiet

Table 1/1

Catalogusnummer	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)	Breedte (W)	Hoogte 1 (H1)	Hoogte 2 (H2)
RBVB11065X	38 mm	279 mm	38 mm	76 mm	165mm	76mm
RBVA7570J	76 mm	191 mm	38 mm	76 mm	178mm	76mm
RBVA9060F	64 mm	229 mm	38 mm	76 mm	152mm	76mm
RBVA9095F	64 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVA9095M	95 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVB12060E	57 mm	305 mm	38 mm	76 mm	152mm	76mm

Catalogusnummer	Diameter (Ø)	Lengte 1 (L1)	Lengte 2 (L2)	Breedte (W)	Hoogte 1 (H1)	Hoogte 2 (H2)
RBVB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBVB12070M	95 mm	305 mm	38 mm	76 mm	178mm	76mm
RBVB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBVB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBVB14080J	64 mm	356 mm	38 mm	76 mm	203mm	76mm
RBVB16575E	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575J	76 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575M	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB17075D	76 mm	432 mm	38 mm	76 mm	191mm	76mm
RBVB17710F	64 mm	451 mm	38 mm	76 mm	254mm	76mm
RBVB17710M	95 mm	451 mm	38 mm	76 mm	254mm	76mm


AANVULLENDE PRODUCTGEGEVENS

RBVA pouring basins require one RBM2660DC pouring basin frame and one RBS5000 bolt retainer. RBVB pouring basins require one RBM2660TC pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMEN

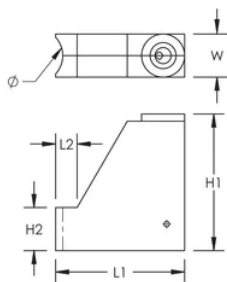

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

Noord-Amerika

+1.800.753.9221

optie 1 – Klantenservice

optie 2 – Technische

ondersteuning

Europa

Nederland:

+31 800-0200135

Frankrijk:

+33 800 901 793

Europa

Duitsland:

800 1890272

andere landen:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE