


# Air Terminal Base, Stamped Adjustable, Imperial Thread

## Power Utilities

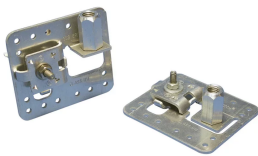

### KENMERKEN

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping

### SPECIFICATIES


Table 1/1

| Catalogusnummer | Geleiderafmeting, UL           | Hoogte (H) | Breedte (W) |
|-----------------|--------------------------------|------------|-------------|
| LPA30212        | Klasse 1 - Klasse 2 (max. 4/0) | 34.92 mm   | 101.600 mm  |

### AANVULLENDE PRODUCTGEGEVENS

Vertical type bases are factory pre-configured for vertical mount applications.

## DIAGRAMMEN

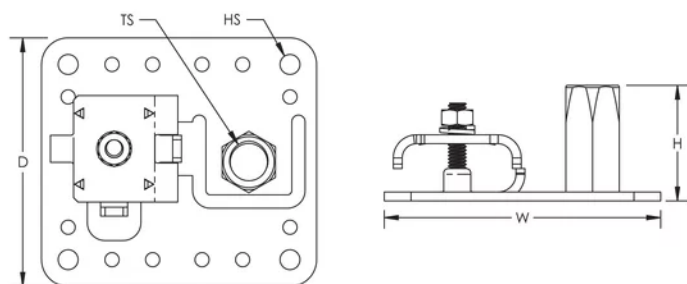

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.



Ons krachtige merkenportfolio:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**