


# Front Panel, U-profile, Refrofit Shielding, 6 U, 84 HP

Energiebedrijven

## CATALOGUSNUMMER

**20848-189**

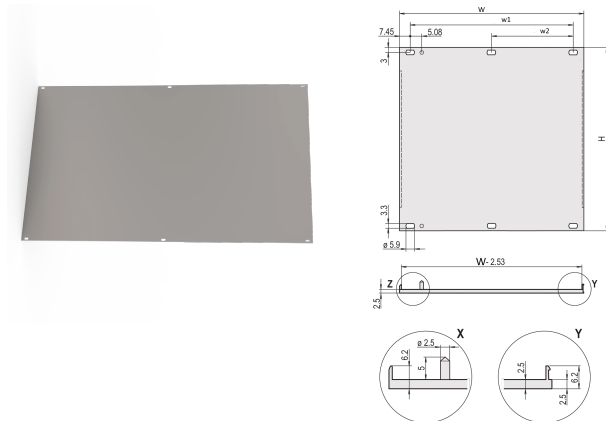

U-profile front panel for textile EMC gasket.

## CERTIFICERINGEN



## KENMERKEN

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

## PRODUCTKENMERKEN

Product Type: Front Panel

Type: Front Panel without Handle

Mounting: Screw-on Front

EMC Shielding: No (Retrofittable)

EMC Gasket Type: Textile

Material: Aluminium

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Nee

Rack Height: 6 U

Height: 261,8 mm

Rack Width: 84 HP

Width: 426,4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

Differences in finish between 2 ... 12 HP and 14 ... 84 HP.

2 ... 12 HP: one-part U-profile

Please order textile EMC gasket separately.

Standard pack quantity: 2 to 28HP: 5 pieces, 42 to 84 HP: 1 piece, supplied in standard pack quantities (SPQ) only.

## WAARSCHUWING

---

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van [www.nvent.com](http://www.nvent.com) of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**