


# Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

## Power Utilities

### CATALOGUSNUMMER

**20848-617**

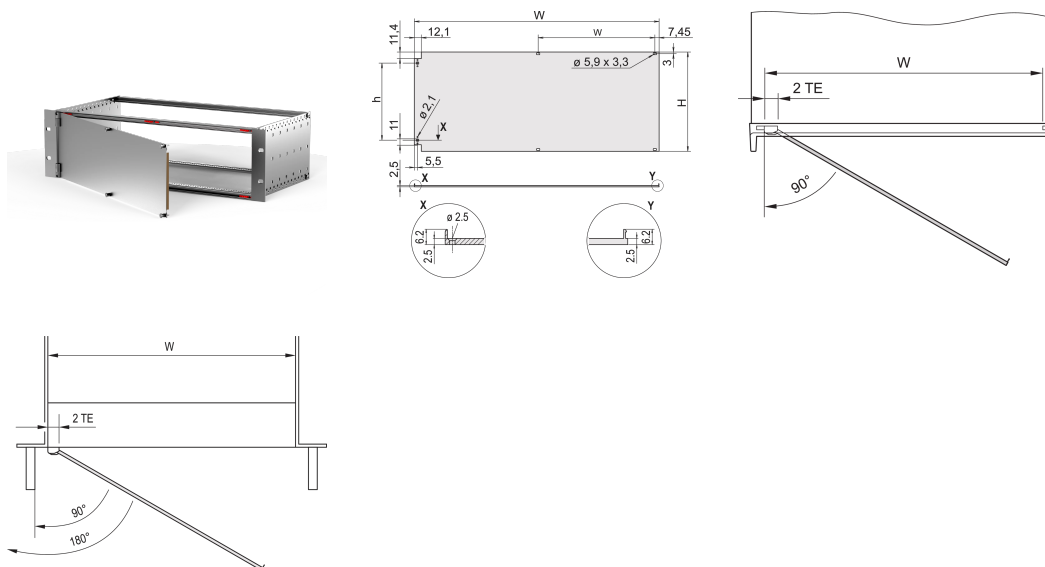

Front panel with textile EMC gasket, side hinged assembly.

### CERTIFICERINGEN



### KENMERKEN

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

## PRODUCTKENMERKEN

Producttype: Voorpaneel

Type: Voorpaneel zonder handgreep

Montage: Scharnierend, zijkant

EMC-afscherming: Nee (achteraf te installeren)

Type pakking: Textile

Materiaal: Aluminium

Afwerking voorzijde: Geanodiseerd

Afwerking achterzijde: Geleidend

Behandelde randen: Nee

Rekhoogte: 6 U

Hoogte: 261.8 mm

Rekbreedte: 84 HP

Breedte: 426.4 mm

Pakkethoeveelheid: 1

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**