


RackPower iPDU, RP1326, 100-240 VAC, 1-phase

Power Utilities

CATALOGUSNUMMER

RP1326

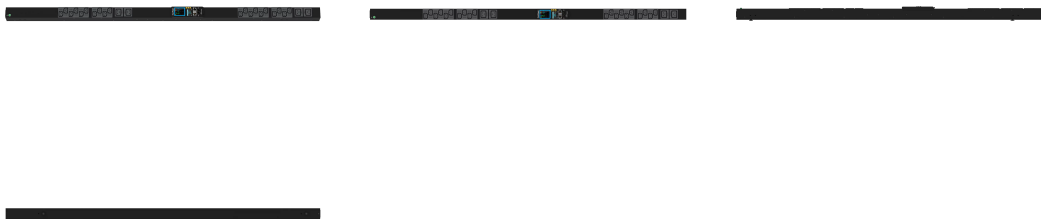

Modular, compact intelligent PDU with inlet metering. Ultra-Low Profile Design with only 44 mm height.

KENMERKEN

RackPower RP1xxx Intelligent Power Distribution Units monitors input power of the entire PDU, provides billing grade unit level monitoring

High Visibility Data Display and Interactive Graphic Display

Measure circuit breaker loads across redundant feeds to avoid accidental downtime

Enables smart load balancing for power efficiency and maximized capacity utilization

Gigabit Ethernet Interface and redundant Ethernet (10/100)

iPDU DC power redundancy solution for up to 64 PDU's

Toolless Hot-Swap Controller

Input Voltage Range 100 - 240 VAC, 1-phase L-N or L-L

Input connector C20

C13, C19 outlets

PRODUCTKENMERKEN

Producttype: Aansluitstrip

Type socket: IEC C13; IEC C19

Kleur: Zwart

Lengte: 1490 mm

AC-spanning: 208 V

Functie: Ingang bewaakt

Diepte: 53 mm

Breedte: 52 mm

AANVULLENDE PRODUCTGEGEVENS

Please order bracket for vertical mounting separately.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE