


EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded

Energiebedrijven

Non-EMC shielded subrack for backplane mounting, light version.

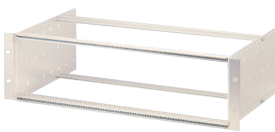

CERTIFICERINGEN



KENMERKEN

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

SPECIFICATIES

Table 1/2

Catalogusnummer	Rack Height	Diepte	Package Quantity	For Mounting	Board Depth	Handle Included
24564-131	3 U	175 mm	1	Backplane	160 mm	Nee
24564-132	3 U	235 mm	1	Backplane	160 mm, 220 mm	Nee
24564-133	3 U	295 mm	1	Backplane	160 mm, 220 mm, 280 mm	Nee
24564-431	6 U	175 mm	1	Backplane	160 mm	Nee
24564-432	6 U	235 mm	1	Backplane	160 mm, 220 mm	Nee
24564-433	6 U	295 mm	1	Backplane	160 mm, 220 mm, 280 mm	Nee

Table 2/2

Catalogusnummer	Montage	Voltoet aan	EMC Shielding	Product Type	Rack Width	Statische belasting
24564-131	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf
24564-132	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf
24564-133	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf
24564-431	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf
24564-432	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf
24564-433	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Nee	Subrack/Chassis	84 HP	7.5 kgf

ADDITIONAL PRODUCT DETAILS

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE