


EuropacPRO 19" Subrack Kit for DIN Connector

Energiebedrijven

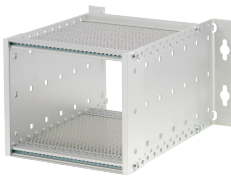

Subrack for assembly to a wall or cabinet panel for Din connector mounting without rear hood.

CERTIFICERINGEN



KENMERKEN

Subrack with side panel type L ("light")

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

For connector mounting (DIN 41612, EN 60602-3)

Horizontal rails type "light"

Aluminum construction

SPECIFICATIES

Table 1/2

Catalogusnummer	Product Type	Rack Height	Rack Width	Diepte	For Mounting	Board Depth
-----------------	--------------	-------------	------------	--------	--------------	-------------

24563-109	Subrack/Chassis	3 U	28 HP	205 mm	DIN Connector	160 mm
-----------	-----------------	-----	-------	--------	---------------	--------

Table 2/2

Catalogusnummer	EMC Shielding	Statische belasting	Handle Included	Montage	Voldoet aan	Package Quantity
24563-109	Nee	2.5 kgf	Nee	Wand	IEC 60297-3-103	1

ADDITIONAL PRODUCT DETAILS

EMC version on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE