


EuropacPRO Rugged Rear Angle for Textile EMC Gasket

Energiebedrijven

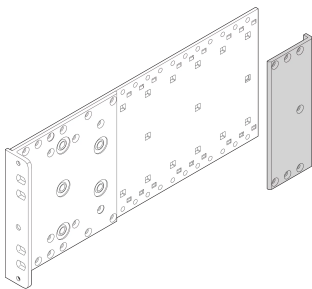

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

CERTIFICERINGEN



KENMERKEN

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

SPECIFICATIES

Table 1/2

Catalogusnummer	Rack Height	Package Quantity	Hoogte	Product Family	Product Type	Type
24566-499	6 U	1	265.9 mm	EuropacPRO	Afdekking	Rugged
24566-197	3 U	1	132.6 mm	EuropacPRO	Afdekking	Rugged

Catalogusnummer	Rack Height	Package Quantity	Hoogte	Product Family	Product Type	Type
24566-199	3 U	1	132.6 mm	EuropacPRO	Afdekking	Rugged
24566-497	6 U	1	265.9 mm	EuropacPRO	Afdekking	Rugged

Table 2/2

Catalogusnummer	Works With	Verpakkingseenheid	Certificeringen
24566-499	Subracks	Paar	RoHS
24566-197	Subracks	Paar	
24566-199	Subracks	Paar	RoHS
24566-497	Subracks	Paar	

ADDITIONAL PRODUCT DETAILS

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE