


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Energiebedrijven

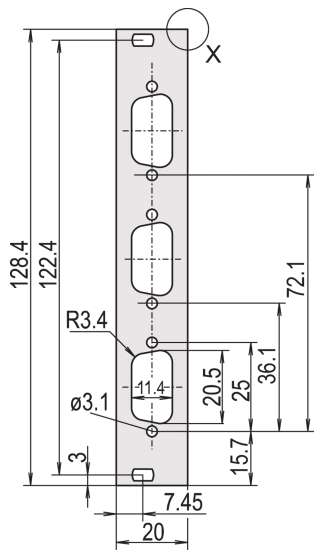

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFICERINGEN



KENMERKEN

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

SPECIFICATIES

Table 1/3						
Catalogusnum mer	Package Quantity	Montage	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges

30118-348	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-349	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-350	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-351	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-352	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-353	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee
30118-354	5	Screw-on Front	Roestvrij staal	Anodized	Conductive	Nee

Table 2/3						
Catalogusnummer	Volddoet aan	EMC Shielding	Hoogte	Materiaal	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U

Table 3/3			
Catalogusnummer	Rack Width	Type	Breedte

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE