


Front Panel, Flat, Unshielded, D-Sub Cutouts

Energiebedrijven

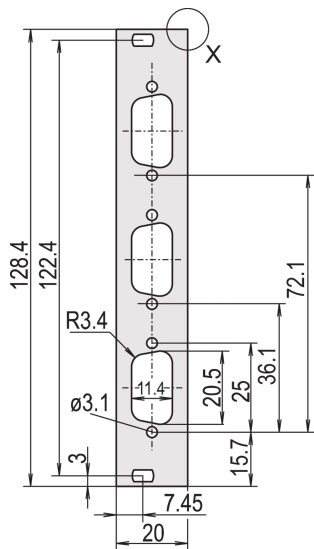

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFICERINGEN



KENMERKEN

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

SPECIFICATIES

Table 1/3

Catalogusnummer	Package Quantity	Montage	Front Finish	Rear Finish	Treated Edges	Voldoet aan
30118-341	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10

Catalogusnummer	Package Quantity	Montage	Front Finish	Rear Finish	Treated Edges	Volddoet aan
30118-342	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodized	Conductive	Nee	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Catalogusnummer	EMC Shielding	Hoogte	Materiaal	Product Type	Rack Height	Rack Width
30118-341	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-342	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-343	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-344	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-345	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-346	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-347	Nee	128.4 mm	Aluminium	Front Panel	3 U	4 HP

Table 3/3

Catalogusnummer	Type	Breedte
30118-341	Front Panel without Handle	20 mm

Catalogusnummer	Type	Breedte
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE