


MI Series Inconel 600 HIQ Heating Cable

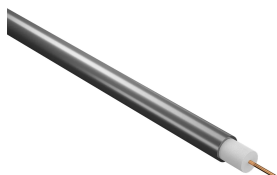

nVent RAYCHEM HIQ Inconel 600 sheathed mineral insulated (MI) series resistance trace heating cables provide freeze protection and process temperature maintenance. They can be used for exposure temperatures up to 700 °C (joint dependent) and typical power outputs up to 300 W/m. Alloy 600 sheath offers excellent corrosion resistance to a wide range of organic acids, alkalis and chloride stress-corrosion cracking. Approved for use in hazardous areas. Available 'fast track' as configured heating units.

KENMERKEN

Reduced total installed cost

Reduced power supply costs: lower start up currents compared with other technologies

Simple controls: current monitoring on series resistance provides instant visibility on critical circuits

Fast track/expedited service for configured heating units for eligible designs

Standard 550 °C continuous withstand temperature, with braze weld technology

Optional 700 °C continuous withstand temperature, with laser welded technology

Excellent corrosion resistance to a wide range of organic acids, alkalis and chloride stress-corrosion cracking

SPECIFICATIES

Min Cable Spacing:	25 mm
Max Power Output:	300 W/m
Max Continuous Exposure Temperature, Power Off:	680 °C
Minimale installatietemperatuur:	-60 °C
Supply Voltage:	0 – 500 V
Area Classification:	Non-Hazardous; Hazardous
Sheath Material:	Inconel 600
Isolatiemateriaal:	Magnesium Oxide

Table 1/1

Catalogusnummer	Nominal Resistance @ 20°C	Buitenste diameter
HIQ1M10K	10000 Ω/km	3.2 mm

Catalogusnummer	Nominal Resistance @ 20°C	Buitenste diameter
HIQ1M4000	4000 Ω/km	3.2 mm
HIQ1M6300	6300 Ω/km	3.2 mm
HIQ1M2500	2500 Ω/km	3.4 mm
HIQ1M1600	1600 Ω/km	3.6 mm
HIQ1M1000	1000 Ω/km	3.9 mm
HIQ1M160	160 Ω/km	6.5 mm
HIQ1M630	630 Ω/km	4.3 mm
HIQ1M400	400 Ω/km	4.7 mm
HIQ1M250	250 Ω/km	5.3 mm

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.

Noord-Amerika

Tel +1.800.545.6258
Fax +1.800.527.5703
thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511
Fax +32.16.213.604
thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688
Fax +86.21.5426.3167
cn.thermal.info@nvent.com

Latijns-Amerika

Tel +1.713.868.4800
Fax +1.713.868.2333
thermal.info@nvent.com

Our powerful portfolio of brands:

RAYCHEM PYROTENAX TRACER NUHEAT