


MTCA.0 System for 2 Single Full-Size AMC Modules, 1 HE

CATALOGUSNUMMER

11850-023

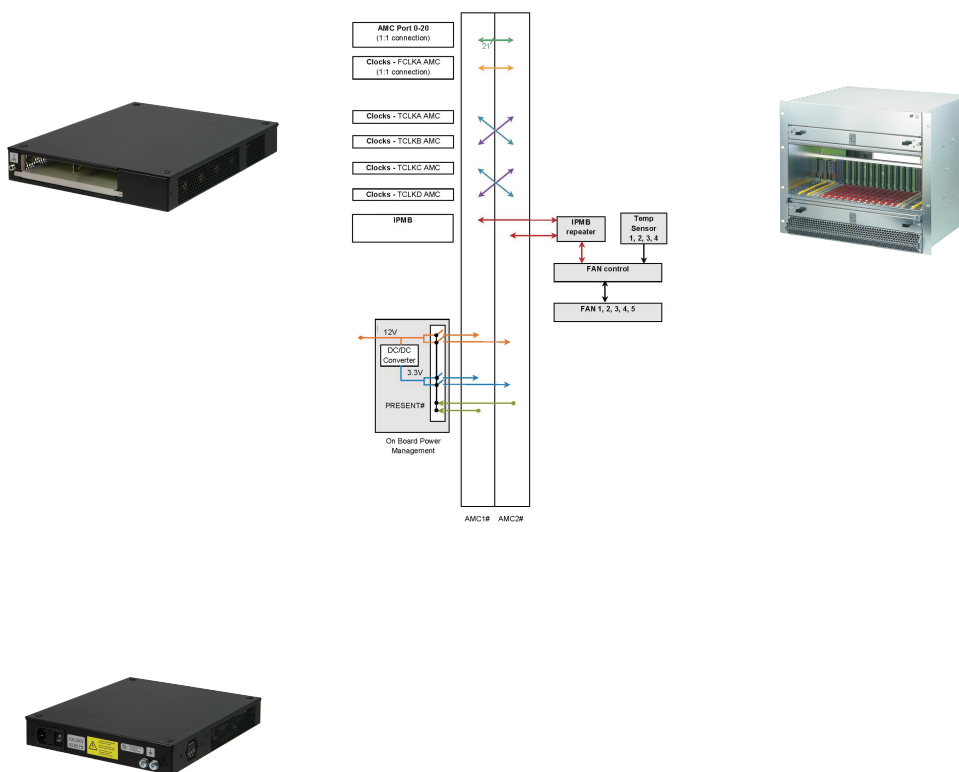

The System is designed for 2 AMC modules. The integrated Power Supply and Power switches on the backplane enable the Payload Power to the AMC Modules without the need for a separate MCH.

CERTIFICERINGEN



KENMERKEN

Small, compact case to hold 2 single full-size AdvancedMC modules With an optional 2 HP filler module, 2 single mid-size modules can also be fitted

Direct connection of all ports between both AdvancedMC slots (see backplane topology); data transfer rates up to 10 Gbps per port

90 - 264 VAC wide range input on rear of case, 150 W power supply in rear section of enclosure

12 VDC voltage is activated by the AdvancedMC module presence signal

150 W cooling capacity at an ambient temperature of 55 °C, airflow from right to left, temperature-regulated fans

Fan unit and fan filter are easy to service or replace

The enclosure is stackable and prepared for plate mounting

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 2

Type: Pico-systeem

Type achterzijde: Alle poorten zijn van punt-naar-punt verbonden

Gegevensoverdracht: 40 GbE; PCIe Gen3

Vermogen per sleuf: 60W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Rechts naar links

Rekhoogte: 1U

Type voeding: Open frame

Voeding inbegrepen: Ja

I/O achter: Nee

Voldoet aan: PICMG MTCA.0 R2.0

Diepte: 302mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

Completely assembled, wired and tested.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE