


VMEbus System, 7 U, 12 Slot, for Transition Modules, Open Frame PSU

CATALOGUSNUMMER

20836-716

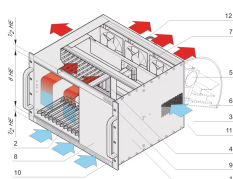

VME system for 12 VME boards 6 U, 160 mm. The power for the system is supplied by an open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICERINGEN



KENMERKEN

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; Backplane conforms to VITA 1.1-1994

PSU, open frame, 444 W (400 W at < 180 VAC)

Backplane VME 12 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

Heat dissipation by 3 fans (rear panel), cooling from front to rear; temperature-controlled with fan control module (FCM)

Display module for DC operating voltages, fan and temperature alarm

System for vertical board mounting with board formats, Front: 6 U, 160 mm deep, Rear: 6 U, 12 HP, 80 mm deep; for transition modules

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 12

Type: 19 inch rekmontage

Type achterzijde: 6 U VME64

Gegevensoverdracht: VME64; VME2eSST

Vermogen per sleuf: 30W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Voor naar achter

Rekhoogte: 7U

Type voeding: Open frame

Voeding inbegrepen: Ja

I/O achter: Ja

Voldoet aan: ANSI/VITA 1.1-1994

Diepte: 355mm

Hoogte: 310.35mm

Breedte: 449mm

Voeding: 450W

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE