


CPCI System, for Pluggable PSU, Horizontal, 4 U, 8 Slot

CATALOGUSNUMMER

24579-106

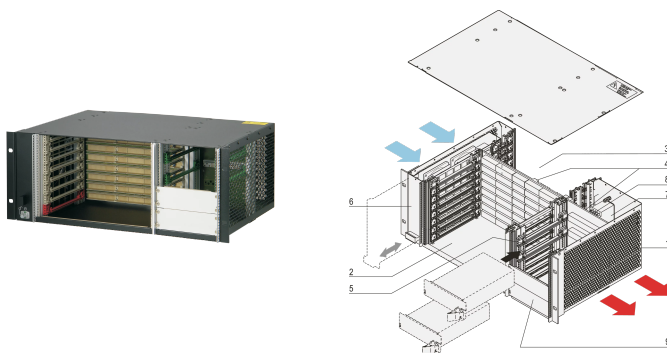

4 U CompactPCI System with horizontal Card Cage for eight 6 U Boards, eighth RTM Boards and two CompactPCI 3 U Pluggable Power Supplies. Option to assemble up to four pluggable Power Supplies.

CERTIFICERINGEN



KENMERKEN

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 8 slot, 6 U, 64 bit, System slot left, Power connector (2 x P 47)

Heat dissipation by hot-swap fan unit (airflow left to right)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

PRODUCTKENMERKEN

Producttype: Systeem

Aantal sleuven: 8

Type: 19 inch rekmontage

Type achterzijde: 6 U CompactPCI

Gegevensoverdracht: 64-bits PCI-bus

Vermogen per sleuf: 40W

Ingangsspanning AC: 100 – 240V

Luchtstroomrichting: Links naar rechts

Rekhoogte: 4U

Type voeding: (2) Insteekbare voeding

Voeding inbegrepen: Nee

I/O achter: Ja

Voldoet aan: PICMG 2,0 R3.0

Diepte: 275mm

Hoogte: 177mm

Breedte: 449mm

Hoeveelheid in verpakking: 1

AANVULLENDE PRODUCTGEGEVENS

Modified systems available on request.

48 VDC version on request.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot producteteringen, schade aan eigendommen, ernstig lichamelijk

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE