


EuropacPRO Advanced EMC 45 Top and Bottom Covers, Screwed to Side Panel, Ø 2.3mm

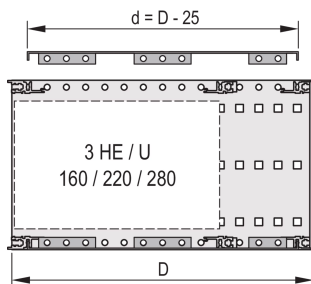

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

CERTIFICERINGEN



KENMERKEN

Top and bottom covers with EMC and airflow optimized perforation, fulfills the requirements of the fire safety standard EN 62368-1, perforation diameter Ø 2.3mm, degree 50%

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

SPECIFICATIES

Materiaal:	Aluminium
Producttype:	Afdekplaat
Productserie:	EuropacPRO
Afwerking:	Geëloxeerd
Type:	Geperforeerd
Werkt met:	Subracks

Table 1/1

Catalogusnummer	Rekbreedte	Diepte	Hoeveelheid in verpakking	Verpakkingseenheid	Snelle verzending
24563-555	36HP	175mm	2	Paar	Nee
24563-556	36HP	235mm	2	Paar	Nee
24563-560	42HP	175mm	2	Paar	Nee
24563-561	42HP	235mm	2	Paar	Nee
24563-562	42HP	275mm	2	Paar	Nee
24563-563	42HP	277.75mm	2	Paar	Nee
24563-564	42HP	295mm	2	Paar	Nee
24563-660	63HP	175mm	2	Paar	Nee
24563-661	63HP	235mm	2	Paar	Nee
24563-662	63HP	275mm	2	Paar	Nee
24563-663	63HP	295mm	2	Paar	Nee
24563-760	84HP	175mm	2	Paar	Nee
24563-761	84HP	235mm	2	Paar	Nee
24563-762	84HP	275mm	2	Paar	Nee
24563-763	84HP	277.75mm	2	Paar	Nee
24563-764	84HP	295mm	2	Paar	Nee
24563-765	84HP	355mm	2	Paar	Nee
24563-766	84HP	415mm	2	Paar	Nee

Catalogusnummer	Rekbreedte	Diepte	Hoeveelheid in verpakking	Verpakkingseenheid	Snelle verzending
24563-767	84HP	495mm	2	Paar	Nee

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE