


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

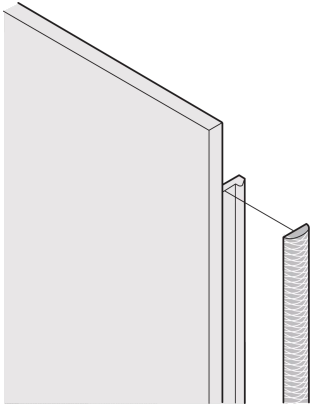

The textile EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels. The gaskets are glued to the front panel.

CERTIFICERINGEN



KENMERKEN

Textile EMC gasket is affixed laterally on the front panel or in the groove of the right-hand profile as appropriate.

Profile seal is bonded onto the contact surface of the 19" bracket or of the rear angle and sets up the conductive connection to the U-shaped front panels

Temperature range -40 °C ... +70 °C

SPECIFICATIES

- Werkt met:** Subracks; Omkastingen; Frontpanelen
- Productserie:** EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Plug-in-eenheid frametype
- Producttype:** Afschermingsset
- Materiaal:** Thermoplastisch elastomeer

Table 1/2

Catalogusnummer	Rekhoogte	Hoeveelheid in verpakking	Diepte (D)	Hoogte (H)	Breedte (W)	Ontvlambaarheidsklasse
-----------------	-----------	---------------------------	------------	------------	-------------	------------------------

21101-853	3U	10	1.62mm	97mm	3.8mm	UL® 94V-0
21101-855	6U	10	1.62mm	232mm	3.8mm	UL® 94V-0
21101-857	2U	10	1.62mm	52mm	3.8mm	UL® 94V-0
21101-859	9U	10	1.62mm	365.5mm	3.8mm	UL® 94V-0
21101-854	3U	100	1.62mm	97mm	3.8mm	UL® 94V-0
21101-856	6U	100	1.62mm	232mm	3.8mm	UL® 94V-0
21101-858	4U	10				
21101-978	5U	10				
21101-904	9U	100				


Table 2/2

Catalogusnummer	Snelle verzending
21101-853	Nee
21101-855	Nee
21101-857	Nee
21101-859	Nee
21101-854	Nee
21101-856	Nee
21101-858	Nee
21101-978	Nee
21101-904	Nee

AANVULLENDE PRODUCTGEGEVENS

EMC gaskets (textile) are required for shielding the front panels.

DIAGRAMMEN

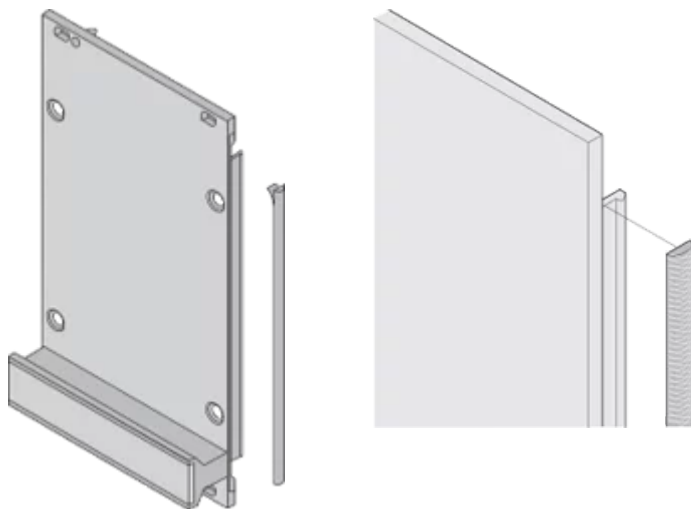

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE