


Interscale Fan Holder With Fans

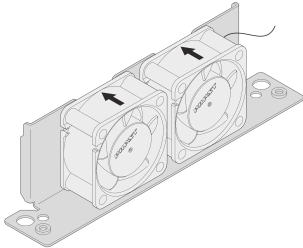

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m³/h.

KENMERKEN

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

SPECIFICATIES

Afwerking: Aluminium-verzinkt

Type: Ventilatorlade

Producttype: Ventilatoreenheid

Ingangsspanning DC: 12V min

Table 1/2

Catalogusnummer	Breedte	Diepte	Hoeveelheid in verpakking	Max. statische druk	Max. omgevingstemperatuur	Luchtstroom
24828-104	40mm	20mm	1		70°C	10m ³ /h
24828-105	40mm	20mm	1		70°C	10m ³ /h
24828-107	40mm	20mm	1		70°C	10m ³ /h

Catalogusnummer	Breedte	Diepte	Hoeveelheid in verpakking	Max. statische druk	Max. omgevingstemperatuur	Luchtstroom
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-307	119mm	25mm	1		70°C	170m³/h
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24830-102	80mm	25mm	1			

Table 2/2						
Catalogusnummer	Geluidsniveau	Hoogte	Materiaal	Voeding	Productserie	Snelle verzending
24828-104	18dB(A)	40mm	Staal	0.9W	Interscale	Nee
24828-105	18dB(A)	40mm	Staal	0.9W	Interscale	Nee
24828-107	18dB(A)	40mm	Staal	0.9W	Interscale	Nee
24828-204	32dB(A)	80mm	Staal	2W	Interscale	Nee
24828-205	32dB(A)	80mm	Staal	2W	Interscale	Nee
24828-207	32dB(A)	80mm	Staal	2W	Interscale	Nee
24828-305	43dB(A)	119mm	Staal	5.3W	Interscale	Nee
24828-307	43dB(A)	119mm	Staal	5.3W	Interscale	Nee
24830-101	44.62dB(A)	80mm	Staal			Nee

Catalogusnummer	Geluidsniveau	Hoogte	Materiaal	Voeding	Productserie	Snelle verzending
24830-102		80mm	Staal			Nee

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE