


# Mounting Plate for 19" Case and Subrack

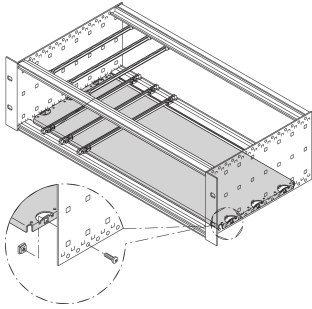

Mounting plate for heavy components or proprietary electronic assemblies. Suitable for RatiopacPRO/-AIR, CompacPRO and EuropacPRO.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## CERTIFICERINGEN



## KENMERKEN

For assembly of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

Mounting plate, partial width: The partial width mounting plate fixed to the side panel by means of an assembly strip

The chassis plate can't be combined with EMC top- / bottom covers

## SPECIFICATIES

**Materiaal:** Aluminium  
**Producttype:** Montageplaat  
**Werkt met:** Subracks

Table 1/2

| Catalogusnummer | Rekbreedte | Hoeveelheid in verpakking | Diepte  | Productserie                                           | Breedte  | Certificeringen |
|-----------------|------------|---------------------------|---------|--------------------------------------------------------|----------|-----------------|
| 34562-750       | 42HP       | 1                         | 172.5mm | EuropacPRO,<br>CompacPRO,<br>RatiopacPRO,<br>PropacPRO | 217.99mm | RoHS            |

| Catalogusnummer | Rekbreedte | Hoeveelheid in verpakking | Diepte  | Productserie                                  | Breedte  | Certificeringen |
|-----------------|------------|---------------------------|---------|-----------------------------------------------|----------|-----------------|
| 34562-746       | 42HP       | 1                         | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 217.99mm | RoHS            |
| 34562-754       | 42HP       | 1                         | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 217.99mm | RoHS            |
| 34562-758       | 42HP       | 1                         | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO            | 217.99mm | RoHS            |
| 34562-752       | 84HP       | 1                         | 172.5mm | EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO | 431.35mm | RoHS            |
| 34562-748       | 84HP       | 1                         | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 324.67mm | RoHS            |
| 34562-756       | 84HP       | 1                         | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 431.35mm | RoHS            |
| 34562-760       | 84HP       | 1                         | 292.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 431.35mm | RoHS            |
| 34562-749       | 28HP       | 1                         | 172.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS            |
| 34562-745       | 28HP       | 1                         | 112.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS            |
| 34562-753       | 28HP       | 1                         | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 146.88mm | RoHS            |
| 34562-751       | 63HP       | 1                         | 172.5mm | EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO | 324.67mm | RoHS            |
| 34562-747       | 63HP       | 1                         | 112.5mm | EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO | 324.67mm | RoHS            |
| 34562-755       | 63HP       | 1                         | 232.5mm | EuropacPRO, RatiopacPRO, CompacPRO            | 324.67mm | RoHS            |

| Catalogusnummer | Rekbreedte | Hoeveelheid in verpakking | Diepte  | Productserie                       | Breedte  | Certificeringen |
|-----------------|------------|---------------------------|---------|------------------------------------|----------|-----------------|
| 34562-759       | 63HP       | 1                         | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO | 324.67mm | RoHS            |
| 34562-870       | 84HP       | 1                         | 352.5mm | EuropacPRO                         | 431.35mm |                 |
| 34562-871       | 84HP       | 1                         | 412.5mm | EuropacPRO                         | 431.35mm |                 |
| 34562-757       | 28HP       | 1                         | 292.2mm | EuropacPRO, RatiopacPRO, CompacPRO | 146.88mm | RoHS            |

Table 2/2

| Catalogusnummer | Snelle verzending |
|-----------------|-------------------|
| 34562-750       | Nee               |
| 34562-746       | Nee               |
| 34562-754       | Nee               |
| 34562-758       | Nee               |
| 34562-752       | Nee               |
| 34562-748       | Nee               |
| 34562-756       | Nee               |
| 34562-760       | Nee               |
| 34562-749       | Nee               |
| 34562-745       | Nee               |
| 34562-753       | Nee               |
| 34562-751       | Nee               |

| Catalogusnummer | Snelle verzending |
|-----------------|-------------------|
| 34562-747       | Nee               |
| 34562-755       | Nee               |
| 34562-759       | Nee               |
| 34562-870       | Nee               |
| 34562-871       | Nee               |
| 34562-757       | Nee               |

## AANVULLENDE PRODUCTGEGEVENS

Please order assembly kit for mounting plate separately.

Other versions on request.

Fixing strips required for partial width, please order separately.

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**