

Plug-In Unit Protection Panel



The panels protect the solder or the component side of a PCB. A coding with a separate coding strip is not possible.

CERTIFICERINGEN



KENMERKEN

Keying/coding with separate keying/coding strip is not possible

Usable connectors in accordance with EN 60603 (DIN 41612): Construction type B, C, D, F, H, R

Stainless steel, 0.8 mm

SPECIFICATIES

Producttype: Deksel
Materiaal: Roestvrij staal


Table 1/1

Catalogusnummer	Hoeveelheid in verpakking	Werkt met	Snelle verzending
20809-371	1	Componentzijde	Nee
30809-571	1	Soldeerzijde	Nee

AANVULLENDE PRODUCTGEGEVENS

PCB is offset to the right by 1 HP.

DIAGRAMMEN

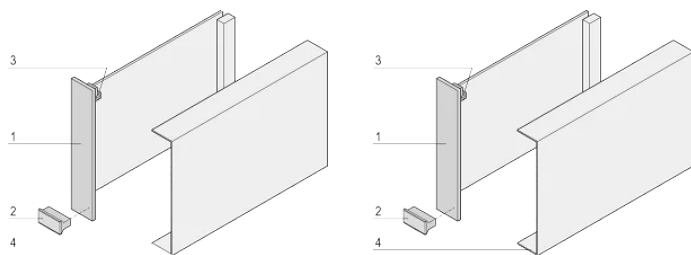

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE