


Plug-In Unit U-Profile Front Panel for XL Handle

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

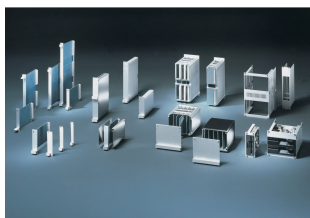

CERTIFICERINGEN



KENMERKEN

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

SPECIFICATIES

Materiaal:	Aluminium
Afwerking:	Geanodiseerd; Geëloxeerd
Type accessoire:	Frontpaneel
Producttype:	Frontpaneel
Type:	Frontpaneel voor handgreep (PIU)
EMC-afscherming:	Nee (achteraf te monteren)

Table 1/3

Catalogusnummer	Rekbreedte	Hoeveelheid in verpakking	Type handgreep	Montage	Type EMC-pakking	Afwerking voorzijde
30849-153	4HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd

Catalogusnummer	Rekbreedte	Hoeveelheid in verpakking	Typehandgreep	Montage	Type EMC-pakking	Afwerking voorzijde
30849-154	4HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd
30849-155	8HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd
30849-156	8HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd
30849-157	12HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd
30849-158	12HP	1	XL	Opschroefbare voorzijde	Textiel	Geanodiseerd

Table 2/3

Catalogusnummer	Afwerking achterzijde	Behandelde randen	Voltoet aan	Diepte (D)	Hoogte (H)	Rekhoogte
30849-153	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U
30849-154	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U
30849-155	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U
30849-156	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U
30849-157	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U
30849-158	Geleidend	Nee	IEC 60297-3-101, IEEE 1101,1/11	2.5mm	261.8mm	6U

Table 3/3

Catalogusnummer	Breedte (W)	Snelle verzending
30849-153	20mm	Nee
30849-154	20mm	Nee
30849-155	40.3mm	Nee

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE