


RatiopacPRO EMC Front Panel, Slotted, Shielded

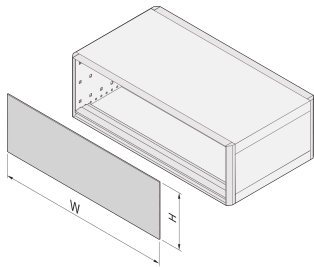

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

CERTIFICERINGEN



KENMERKEN

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

SPECIFICATIES

Materiaal:	Aluminium
Afwerking:	Geanodiseerd; Geëloxeerd
Type accessoire:	Frontpaneel
Producttype:	Frontpaneel

Table 1/2

Catalogusnummer	Rekhoogte	Rekbreedte	Hoeveelheid in verpakking	Afwerking voorzijde	Afwerking achterzijde	Behandelde randen
24572-603	3U	28HP	1	Geanodiseerd	Geleidend	Nee
24572-604	3U	42HP	1	Geanodiseerd	Geleidend	Nee

Catalogusnummer	Rekhoogte	Rekbreedte	Hoeveelheid in verpakking	Afwerking voorzijde	Afwerking achterzijde	Behandelde randen
24572-605	3U	63HP	1	Geanodiseerd	Geleidend	Nee
24572-606	3U	84HP	1	Geanodiseerd	Geleidend	Nee
24572-607	4U	28HP	1	Geanodiseerd	Geleidend	Nee
24572-608	4U	42HP	1	Geanodiseerd	Geleidend	Nee
24572-609	4U	63HP	1	Geanodiseerd	Geleidend	Nee
24572-610	4U	84HP	1	Geanodiseerd	Geleidend	Nee
24572-599	2U	28HP	1	Geanodiseerd	Geleidend	Nee
24572-600	2U	42HP	1	Geanodiseerd	Geleidend	Nee
24572-601	2U	63HP	1	Geanodiseerd	Geleidend	Nee
24572-602	2U	84HP	1	Geanodiseerd	Geleidend	Nee

Table 2/2

Catalogusnummer	Diepte	Hoogte	Breedte	Snelle verzending
24572-603	2.5mm	128.4mm	141.9mm	Nee
24572-604	2.5mm	128.4mm	213.2mm	Nee
24572-605	2.5mm	128.4mm	319.7mm	Nee
24572-606	2.5mm	128.4mm	426.4mm	Nee
24572-607	2.5mm	172.9mm	141.9mm	Nee
24572-608	2.5mm	172.9mm	213.2mm	Nee
24572-609	2.5mm	172.9mm	319.7mm	Nee

Catalogusnummer	Diepte	Hoogte	Breedte	Snelle verzending
24572-610	2.5mm	172.9mm	426.4mm	Nee
24572-599	2.5mm	84mm	141.9mm	Nee
24572-600	2.5mm	84mm	213.2mm	Nee
24572-601	2.5mm	84mm	319.7mm	Nee
24572-602	2.5mm	84mm	426.4mm	Nee

AANVULLENDE PRODUCTGEGEVENS

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Ons krachtige merkenportfolio:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE