


# Static Handle Plastic in Trapezoid Form, Black

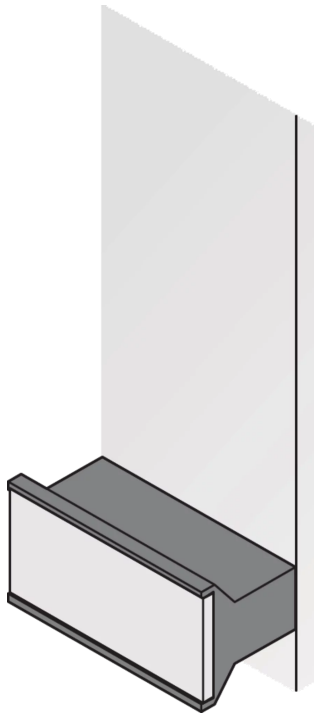

The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

## CERTIFICERINGEN



## KENMERKEN

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

## SPECIFICATIES

|                     |               |
|---------------------|---------------|
| <b>Werkt met:</b>   | Frontpanelen  |
| <b>Producttype:</b> | Greep         |
| <b>Materiaal:</b>   | Polycarbonaat |
| <b>Type:</b>        | Statisch      |

Table 1/2

| Catalogusnummer | Rekbreedte | Hoeveelheid in verpakking | Type handgreep      | Ontvlambaarheidsklasse | Kleur | Voldoet aan                               |
|-----------------|------------|---------------------------|---------------------|------------------------|-------|-------------------------------------------|
| 20808-080       | 5HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-081       | 6HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-082       | 7HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-083       | 8HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-084       | 9HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-085       | 10HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-086       | 12HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-087       | 14HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-088       | 21HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-089       | 28HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20808-090       | 40HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |

| Catalogusnummer | Rekbreedte | Hoeveelheid in verpakking | Typehandgreep       | Ontvlambaarheidsklasse | Kleur | Voldoet aan                               |
|-----------------|------------|---------------------------|---------------------|------------------------|-------|-------------------------------------------|
| 20808-091       | 42HP       | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20809-396       | 3HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |
| 20809-397       | 4HP        | 1                         | Trapezium, statisch | UL® 94V-0              | Zwart | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 |

Table 2/2

| Catalogusnummer | Breedte (W) | Snelle verzending |
|-----------------|-------------|-------------------|
| 20808-080       | 24mm        | Nee               |
| 20808-081       | 29mm        | Nee               |
| 20808-082       | 34.1mm      | Nee               |
| 20808-083       | 39.2mm      | Nee               |
| 20808-084       | 44.3mm      | Nee               |
| 20808-085       | 49.4mm      | Nee               |
| 20808-086       | 59.6mm      | Nee               |
| 20808-087       | 69.7mm      | Nee               |
| 20808-088       | 105.2mm     | Nee               |
| 20808-089       | 140.8mm     | Nee               |
| 20808-090       | 201.8mm     | Nee               |
| 20808-091       | 212mm       | Nee               |


| Catalogusnummer | Breedte (W) | Snelle verzending |
|-----------------|-------------|-------------------|
| 20809-396       | 13.8mm      | Nee               |
| 20809-397       | 18.9mm      | Nee               |

## AANVULLENDE PRODUCTGEGEVENS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

## DIAGRAMMEN

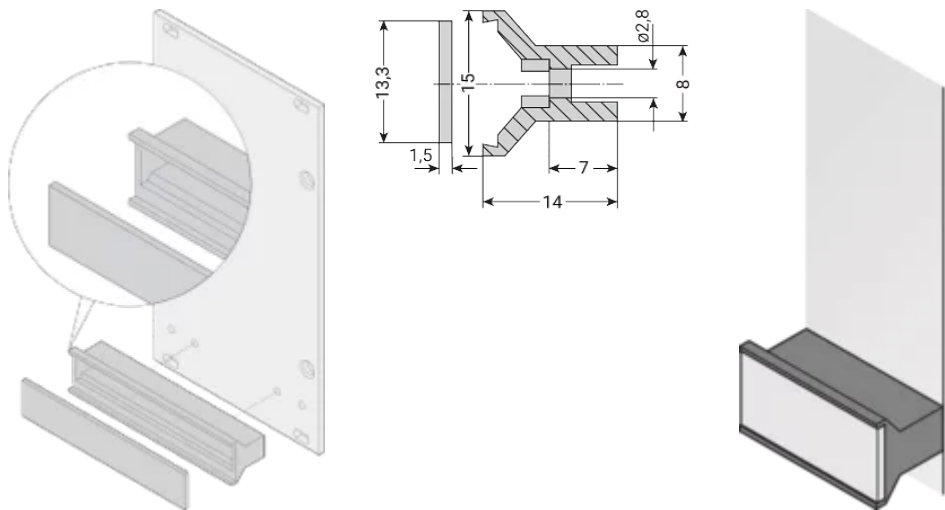

## WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op [www.nvent.com](http://www.nvent.com) en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Ons krachtige merkenportfolio:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**