

nVent ERIFLEX Flexbus HCBC Plate

Data Solutions



SERTIFISERINGER



FUNKSJONER

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPESIFIKASJONER

Materiale: Kobber

Overflate: Tinnbelagt

Table 1/2

Katalognummer	Artikkelnummer	A	B	C	D	Tykkelse (T)
---------------	----------------	---	---	---	---	--------------

FLEXPLATE50	508180	65mm	63mm	45mm	41mm	5mm
FLEXPLATE100	508181	115mm	63mm	45mm	51mm	5mm


Table 2/2

Katalognummer	Artikkelnummer	Lederstørrelse	Enhetsvekt
FLEXPLATE50	508180	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.16kg
FLEXPLATE100	508181	960 mm ² , 1280 mm ² , 1810 mm ²	0.32kg

YTTERLIGERE PRODUKTDETALJER

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

DIAGRAMMER

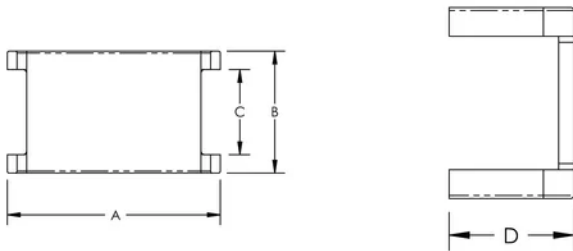

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE