

RackChiller CDU800 kjøleenhet

Data Solutions



The nVent HOFFMAN RackChiller CDU800 is designed for efficient and safe supply of IT equipment. The entire system is focused on providing the highest reliability, availability, and serviceability for supporting direct-to-chip liquid cooling. The CDU800 is fed from a primary facility water system (FWS), where the integrated pumps drive the secondary technology cooling system (TCS) cooling loop flow. The heat exchanger transfers the excess heat from the secondary coolant to the primary. The complete system is integrated into an aesthetical enclosure with removable side panels and doors. The CDU can be installed onto a slab or raised floor, in-row with equipment racks or into a separate facility room.

BRANSJESTANDARDER

UL/cUL Listed; File No. SA7402

CE

FUNKSJONER

800+kW of cooling capacity @ 6K (850 LPM Primary)

Redundant high-performance, leak-free pump system

Integrated variable speed drives

Coolant connections through top or bottom panel

Integrated 10-inch touch panel display

Remote control features through Ethernet, SNMP v3, Modbus

On-board integrated leak detection

Unrivalled power density – fits into standard data center footprint

Serviceable during operation – no need for shut down during system maintenance

Redundant system layout minimizes risk for single points of failure

Integrates with nVent Guardian Management Gateway and sensors portfolio

SPESIFIKASJONER




Farge: Svart grå

Materiale: Mild stål
Avslutt: Belagt
Fargekode: RAL 7021

Table 1/2						
Katalognummer	Høyde (H)	Bredde (W)	Dybde (D)	Spenningsklasse	Faseantall	Nominell frekvens
CDU8004LA03B	2200mm	800mm	1200mm	380 – 480V	3	50 – 60Hz
CDU8004LA03A	2200mm	800mm	1200mm	380 – 480V	3	50 – 60Hz

Table 2/2						
Katalognummer	Nominell strøm/merkespenning	Strømforbruk	Opprinnelsesland	Nominell belastning nåværende område	Støynivå	Type
CDU8004LA03B	40	22.2W	United States	47.5A min	68dB	Med primærfiltrering
CDU8004LA03A	40	22.2W	United States	47.5A min	68dB	Med primærfiltrering

DIAGRAMMER

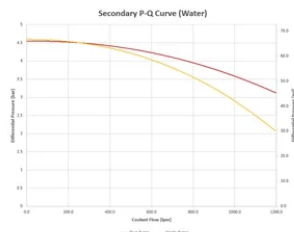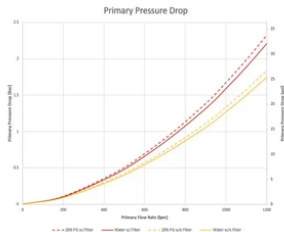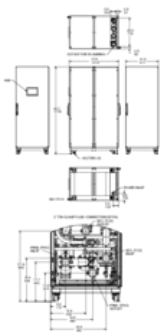

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE