


nVent ERIFLEX Flexbus HCBC klemme

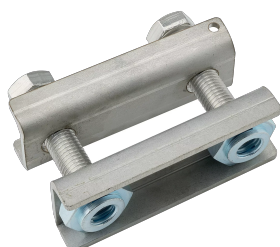

SERTIFISERINGER



FUNKSJONER

Installeres raskt og enkelt

I samsvar med RoHS

Rigid design assures even contact pressure

Ideal for on-site modifications

Made with non-magnetic material stainless steel for high-current connections to prevent the formation of magnetic fields

Contains crimped self-locking nut for vibration resistance and easy installation

No drilling needed to fix the Flexbus Conductor on the transformer/power supply palm

Includes voltage detection connecting point

SPESIFIKASJONER

Materiale: Rustfritt stål 304 (en 1,4301)

Table 1/2

Katalognummer	Artikkelnummer	A	B.	C.	D	Tykkelse (T)
---------------	----------------	---	----	----	---	--------------

FLEXCLAMP63	508190	63 mm	123 mm	20 mm	43 mm	4 mm
FLEXCLAMP80	508191	80 mm	140 mm	20 mm	43 mm	4 mm
FLEXCLAMP160	508194	160 mm	220 mm	20 mm	43 mm	4 mm
FLEXCLAMP100	508192	100 mm	160 mm	20 mm	43 mm	4 mm
FLEXCLAMP120	508193	120 mm	180 mm	20 mm	43 mm	4 mm

Table 2/2


Katalognummer	Artikkelnummer	Hullstørrelse (HS)	Tiltrekkingsmoment (TQ)	Vekt på enhet	Lederbredde
FLEXCLAMP63	508190	5.5 mm	100 N·m	0.53 kg	30 - 63 mm
FLEXCLAMP80	508191	5.5 mm	100 N·m	0.84 kg	70 - 80 mm
FLEXCLAMP160	508194	5.5 mm	100 N·m	1.32 kg	130 - 160 mm
FLEXCLAMP100	508192	5.5 mm	100 N·m	0.92 kg	90 - 100 mm
FLEXCLAMP120	508193	5.5 mm	100 N·m	1 kg	110 - 120 mm

YTTERLIGERE PRODUKTDETALJER

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

The minimum clearance distance is 14mm according to IEC 61439-1 with air pollution degree 3. If this distance cannot be respected, insulation material should be added between the metallic LV cover and the HCBC clamp. Flexbus IP2x Boots is also a solution.

If the Flexbus Conductors have a horizontal entry, an extender needs to be added between the power supply palm and HCBC Clamp and Plate.

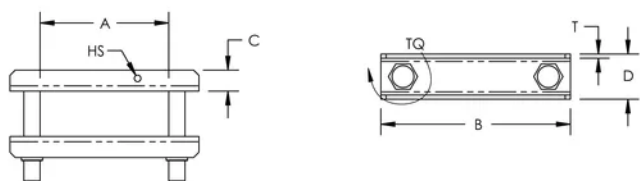

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

Nord-Amerika

+1.800.753.9221

Alternativ 1 –

Kundeservice

Alternativ 2 – Teknisk
støtte

Europa

Nederland:

+31 800-0200135

Frankrike:

+33 800 901 793

Europa

Tyskland:

800 1890272

Andre land:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE