


Barrier Kits brakett-montert

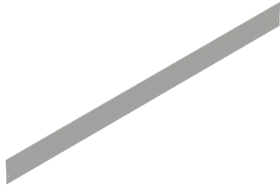

Divides wireway into two or three compartments. Plated spring steel brackets hold barriers in place by friction fit inside wireway. Order barrier and bracket separately. Recommended spacing increments of 3 ft.

FUNKSJONER

Divides wireway into two or three compartments

Plated spring steel brackets hold barriers in place by friction fit inside wireway

Order barrier and bracket separately. Recommended spacing increments of 3 feet

SPESIFIKASJONER

Fargekode:	ANSI 61
Overflate:	Galvanisert; Pulverlakkert
Farge:	Grå
Materiale:	Mild stål

Table 1/1

Katalognummer	Type	Høyde	Bredde	Dybde	Tykkelse	Hurtiglevering
F44BB2C	Barrier Kit	102mm	102mm	25mm	1.9mm	Nei
F66BB2C	Barrier Kit	152mm	152mm	25mm	1.9mm	Nei
F44BB3C	Barrier Kit	102mm	102mm		1.9mm	Nei
F44B360	Barrier Kit	102mm	102mm	1524mm	1.9mm	Nei
F66B560	Barrier Kit	152mm	152mm	3048mm	1.9mm	Nei
F66BB3C	Barrier Kit	152mm	152mm		1.9mm	Nei

YTTERLIGERE PRODUKTDETALJER

Sealing Plates package consists of five barriers or five brackets. Each barrier is 60 inches long.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE