


Cable Entry Gland Plate Connected Grommet Small, CCFGS

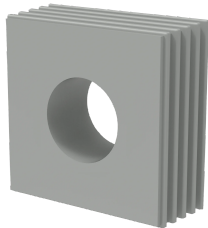

CCFGS cable glands are used with CCFI, CCFO and CCFR cable entry systems.

BRANSJESTANDARDER

UL 508A Component Recognized; Type 1, 12, 4X (indoor only); File No. E61997

UL94 V-0 Flammability

NEMA Type 1, 12, 4X (indoor only)

CE

IP66

FUNKSJONER

IP66 Modular Halogen-free and silicone free cable entry system, that provide versatility, variability and variety

Everything mounted from the outside of the enclosure

The frames, inlays and grommets can be combined in many ways - ensuring you many versatile configuration options

The frame does not need to be disassembled if requirements change or carrying out service work

No need to disassemble and reconnect connectors on cables so manufactures warranty is not voided

The conical shape of the grommets allows them to be easily pressed in, provides static strain relief in accordance with DIN EN 62444

For assembly, they are pressed from the inside out into the openings of the assembled inlays

The grommets are available in different sizes to match the diameter of the cable

The CCFGS is first placed around the cable and then inserted into the cable gland

Based on the wave-cut profile, there is no need to remove the connector on the assembled cabled

SPESIFIKASJONER

Table 1/1						
Katalognummer	Høyde	Bredde	Dybde	Materiale	Overflate	Farge
CCFGS15	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS14	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS12	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS13	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS10	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS11	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS8	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS9	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS6	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS7	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS2	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS4	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS5	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS015	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå
CCFGS3	20.3mm	20.3mm	17.7mm	Plast	Ubehandlet	Grå

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieill. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE